

**Industrial Ethernet
IE-TO-LCD-SM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



Mounting rail outlet, LC duplex junction design according
to IEC 61754-20

General ordering data

Type	IE-TO-LCD-SM
Order No.	8947020000
Version	Mounting rail outlet, fibre-optic, LC Duplex, Singlemode, IP20
GTIN (EAN)	4032248735037
Qty.	10 pc(s).

**Industrial Ethernet
IE-TO-LCD-SM**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	35 g
------------	------

Temperatures

Operating temperature, max.	70 °C	Operating temperature, min.	-40 °C
Operating temperature	-40 °C...70 °C	Storage temperature	
Temperature range, installation, min.	-25 °C	Installation temperature	
Temperature range, installation, max.	70 °C		

General data

Colour	Light Grey	Connection 1	LC Duplex
Connection 2	LC Duplex	Fibre type	Singlemode
Housing main material	PA UL 94 V0	Insertion loss	≤ 0.5 dB
Plugging cycles	1000	Protection degree	IP20
Type of mounting	TS 35		

Standards

Connector standard	IEC 61754-20
--------------------	--------------

Classifications

ETIM 3.0	EC000018	ETIM 4.0	EC000018
ETIM 5.0	EC000018	ETIM 6.0	EC000313
UNSPSC	30-21-18-01	eClass 6.2	27-25-05-04
eClass 7.1	27-25-05-04	eClass 8.1	19-17-01-25
eClass 9.0	27-44-03-20	eClass 9.1	19-17-01-25

Approvals

Approvals



ROHS	Conform
------	---------

Downloads


Brochure/Catalogue	CAT 9 IETH 15/16 EN FL FIELDWIRING EN PI PROFINET CABLING EN
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN

Industrial Ethernet IE-TO-LCD-SM

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Dimensioned drawing

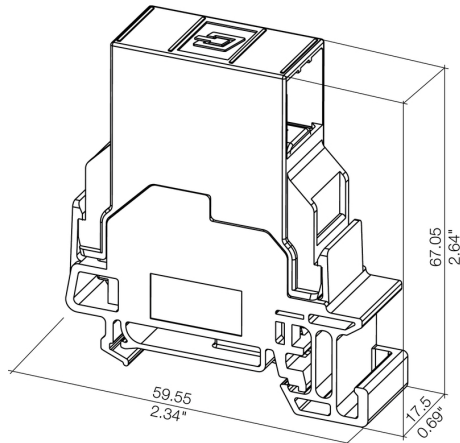

Drawing

