

Connecting elements
H16,0/25,5X BL SV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

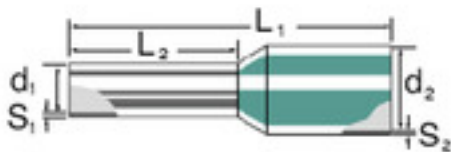

- In multi-pack bag
- Weidmüller colour code

General ordering data

Type	H16,0/25,5X BL SV
Order No.	9006870000
Version	Wire-end ferrule, insulated, 26 mm, 12 mm, blue
GTIN (EAN)	4008190332327
Qty.	100 pc(s).
Packaging	Multipack bag

Connecting elements

H16,0/25,5X BL SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	25.5 mm	Width (inches)	1.004 inch
Net weight	0.93 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	11.9 mm	Colour code	Weidmüller
Conductor cross-section	16 mm ²	Contact surface diameter (D1)	6 mm
Contact surface length (L2)	12 mm	L1 in mm	25.5 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.3 mm
Stripping length	26 mm	Wire connection cross section AWG, max.	AWG 6

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Connecting elements H16,0/25,5X BL SV

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Drawings

Similar to illustration

