


Connecting elements H2,5/19T ZH GR SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

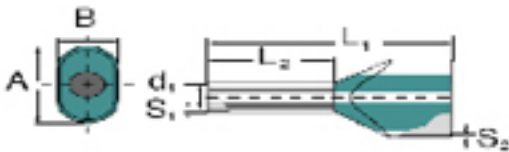

- in multi-pack bag (5 x 100 pcs.)
- DIN colour code
- other colour code

General ordering data

Type	H2,5/19T ZH GR SV
Order No.	9018580000
Version	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, grey
GTIN (EAN)	4008190272647
Qty.	250 pc(s).
Packaging	Multipack bag

Data sheet

**Connecting elements
H2,5/19T ZH GR SV**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	19 mm	Width (inches)	0.748 inch
Net weight	0.324 g		

Technical data

Version	Twin wire-end ferrule
---------	-----------------------

Wire-end ferrules

Collar height (A)	8 mm	Collar width (B)	4.5 mm
Colour code	Telemecanique	Conductor cross-section	2.5 mm ²
Contact surface diameter (D1)	2.8 mm	Contact surface length (L2)	10 mm
L1 in mm	19 mm	Metal sleeve thickness (S1)	0.15 mm
Plastic collar thickness (S2)	0.4 mm	Stripping length	13 mm
Wire connection cross section AWG, max.	AWG 14		

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS Conform

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet

**Connecting elements
H2,5/19T ZH GR SV**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Similar to illustration

