


Connecting elements H1,0/15S ZH GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

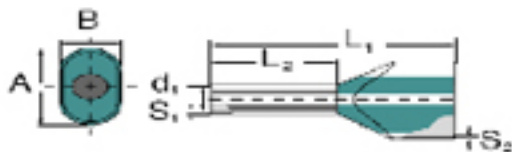

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,0/15S ZH GE
Order No.	9018690000
Version	Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, yellow
GTIN (EAN)	4032248017720
Qty.	500 pc(s).
Packaging	loose

Connecting elements

H1,0/15S ZH GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	15 mm	Width (inches)	0.591 inch
Net weight	0.16 g		

Technical data

Version	Twin wire-end ferrule
---------	-----------------------

Wire-end ferrules

Collar height (A)	5.8 mm	Collar width (B)	3.2 mm
Colour code	Weidmüller	Conductor cross-section	1 mm ²
Contact surface diameter (D1)	2.2 mm	Contact surface length (L2)	8 mm
L1 in mm	15 mm	Metal sleeve thickness (S1)	0.15 mm
Plastic collar thickness (S2)	0.3 mm	Stripping length	12 mm
Wire connection cross section AWG, max.	AWG 17		

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Connecting elements H1,0/15S ZH GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Drawings

Similar to illustration

