

Connecting elements
H0,75/12D GR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

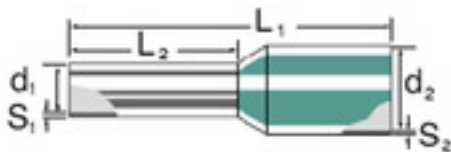

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/12D GR
Order No.	9019030000
Version	Wire-end ferrule, insulated, 8 mm, 6 mm, grey
GTIN (EAN)	4008190127787
Qty.	500 pc(s).
Packaging	loose

Connecting elements

H0,75/12D GR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	12 mm	Width (inches)	0.472 inch
Net weight	0.076 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	2.8 mm	Colour code	DIN
Conductor cross-section	0.75 mm ²	Contact surface diameter (D1)	1.2 mm
Contact surface length (L2)	6 mm	L1 in mm	12 mm
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 005 A
Plastic collar thickness (S2)	0.25 mm	Stripping length	8 mm
Wire connection cross section AWG, max.	AWG 18		

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet**Connecting elements
H0,75/12D GR**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings**Similar to illustration**