

Connecting elements
H4,0/20T OR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

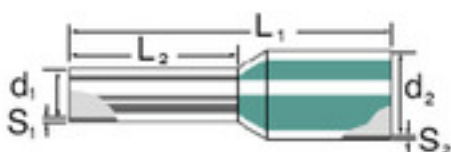

- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

Type	H4,0/20T OR
Order No.	9021110000
Version	Wire-end ferrule, insulated, 14 mm, 12 mm, orange
GTIN (EAN)	4008190035754
Qty.	500 pc(s).
Packaging	loose

Connecting elements

H4,0/20T OR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	20 mm	Width (inches)	0.787 inch
Net weight	0.29 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	4.8 mm	Colour code	Miscellaneous
Conductor cross-section	4 mm ²	Contact surface diameter (D1)	2.8 mm
Contact surface length (L2)	12 mm	L1 in mm	20 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 023 A
Plastic collar thickness (S2)	0.3 mm	Stripping length	14 mm
Wire connection cross section AWG, max.	AWG 12		

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet**Connecting elements
H4,0/20T OR**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings**Similar to illustration**