

Connecting elements
H1,5/14S SW**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

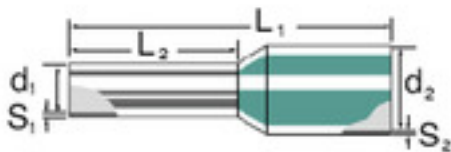

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H1,5/14S SW
Order No.	9025240000
Version	Wire-end ferrule, insulated, 10 mm, 8 mm, black
GTIN (EAN)	4008190085599
Qty.	500 pc(s).
Packaging	loose

Connecting elements

H1,5/14S SW

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	14 mm	Width (inches)	0.551 inch
Net weight	0.126 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	3.9 mm	Colour code	Weidmüller
Conductor cross-section	1.5 mm ²	Contact surface diameter (D1)	1.7 mm
Contact surface length (L2)	8 mm	L1 in mm	14 mm
Metal sleeve thickness (S1)	0.15 mm	Plastic collar thickness (S2)	0.25 mm
Stripping length	10 mm	Wire connection cross section AWG, max.	AWG 16

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN CAT 2 PORTFOLIOGUIDE EN
Engineering Data	WSCAD, EPLAN
Engineering Data	STEP

Data sheet**Connecting elements
H1,5/14S SW**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings**Similar to illustration**