

**Connecting elements
H1,0/14S GE SV****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

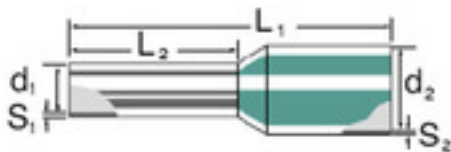

- In multi-pack bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,0/14S GE SV
Order No.	9025710000
Version	Wire-end ferrule, insulated, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190031442
Qty.	500 pc(s).
Packaging	Multipack bag

Connecting elements

H1,0/14S GE SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	14 mm	Width (inches)	0.551 inch
Net weight	0.116 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	3.5 mm	Colour code	Weidmüller
Conductor cross-section	1 mm ²	Contact surface diameter (D1)	1.4 mm
Contact surface length (L2)	8 mm	L1 in mm	14 mm
Metal sleeve thickness (S1)	0.15 mm	Plastic collar thickness (S2)	0.25 mm
Stripping length	10 mm	Wire connection cross section AWG, max.	AWG 17

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	WSCAD, EPLAN
Engineering Data	STEP

Connecting elements H1,0/14S GE SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Similar to illustration

