


Connecting elements H0,14/12 GR SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

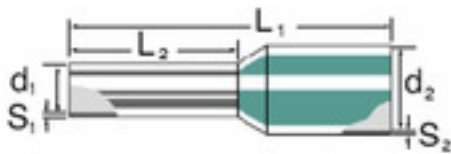

- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Type	H0,14/12 GR SV
Order No.	9028240000
Version	Wire-end ferrule, insulated, 10 mm, 8 mm, grey
GTIN (EAN)	4008190902001
Qty.	500 pc(s).
Packaging	Multipack bag

Data sheet

**Connecting elements
H0,14/12 GR SV**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	12 mm	Width (inches)	0.472 inch
Net weight	0.056 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	1.5 mm	Colour code	Weidmüller
Conductor cross-section	0.14 mm ²	Contact surface diameter (D1)	0.6 mm
Contact surface length (L2)	8 mm	L1 in mm	12 mm
Metal sleeve thickness (S1)	0.15 mm	Plastic collar thickness (S2)	0.25 mm
Stripping length	10 mm	Wire connection cross section AWG, max.	AWG 26

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS Conform

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet

**Connecting elements
H0,14/12 GR SV**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Similar to illustration

