

Connecting elements
H 10,0/22 S EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

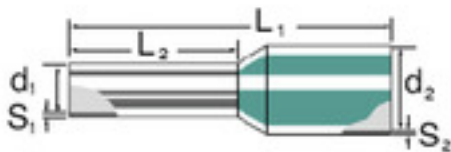

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H 10,0/22 S EB
Order No.	9203620000
Version	Wire-end ferrule, insulated, 15 mm, 12 mm, Ivory
GTIN (EAN)	4032248565061
Qty.	100 pc(s).
Packaging	loose

Connecting elements

H 10,0/22 S EB

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	22 mm	Width (inches)	0.866 inch
Net weight	0.51 g		

Technical data

Version	insulated
---------	-----------

Wire-end ferrules

Collar diameter (D2)	7.1 mm	Colour code	Miscellaneous
Conductor cross-section	10 mm ²	Contact surface diameter (D1)	4.6 mm
Contact surface length (L2)	12 mm	L1 in mm	22 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.6 mm
Stripping length	15 mm	Wire connection cross section AWG, max.	AWG 8

Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 6 TOOLS 15/16 EN
Engineering Data	WSCAD, EPLAN
Engineering Data	STEP

Connecting elements H 10,0/22 S EB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Drawings

Similar to illustration

