

CS64U / CS64US


4-Port USB KVM Switch

The CS64U/CS64US takes a giant step forward from prior cable KVM models in the Petite series, by offering built-in cables, USB peripheral sharing, and a firmware upgrade function that allows you to keep up with latest available versions.

Furthermore, the CS64U/CS64US features enhanced Video DynaSync™ technology, which stores the console monitor's EDID (Extended Display Identification Data) to optimize display resolution. The CS64U/CS64US also offers multiplatform support and computer selection via hotkeys to provide the ultimate in desktop convenience.

Setup

PETITE™

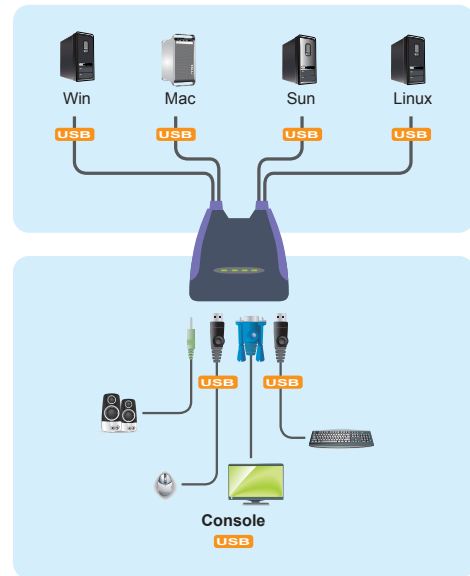

Features

- One USB console controls four USB computers
 - USB mouse port can be used for USB 1.1 hub and USB 1.1 peripheral sharing
 - Computer selection via hotkeys
 - Select OS via Hotkey
 - Audio-enabled
 - Multiplatform support – Windows, Linux, Mac and Sun
 - Compact design, built-in 1.8m cables (CS64U), 0.9/1.2m cables (CS64US)
 - Superior video quality – up to 2048 x 1536; DDC2B
 - Video DynaSync™ – Exclusive ATEN technology eliminates boot-up display problems and optimizes resolution when switching between ports
 - Supports multimedia keyboards
 - Supports wireless keyboards and mice
 - Supports multifunction mice
 - Sun/Mac keyboard support and emulation*
 - Auto Scan function to monitor computer operation
 - Non-Powered
 - Firmware upgradable
- * 1. PC keyboard combinations emulate Sun/Mac keyboards
2. Sun/Mac keyboards only work with their own computers

Specifications

Function		CS64U	CS64US
Computer Connections		4	
Port Selection		Hotkeys	
Connectors	Console Ports	Keyboard	1 x USB Type A Female (White)
		Video	1 x HDB-15 Female (Blue)
		Mouse	1 x USB Type A Female (White)
		Speaker	1 x Mini Stereo Jack Female (Green)
	KVM Ports	Keyboard / Mouse	4 x USB Type A Male (White)
		Video	4 x HDB-15 Male (Blue)
Speaker		4 x Mini Stereo Plug Male (Green)	
LEDs	Selected	4 (Green)	
Cable Length		1.8 m	2 x 0.9 m; 2 x 1.2 m
Emulation	Keyboard / Mouse	USB	
Video		2048 x 1536; DDC2B	
Scan Interval		1-99 secs. (default 5 secs.)	
Environment	Operating Temp.	0-50°C	
	Storage Temp.	-20-60°C	
	Humidity	0-80% RH, Non-condensing	
Physical Properties	Housing	Plastic	
	Weight	0.80 kg	0.77kg
	Dimensions (L x W x H)	10.90 x 9.72 x 2.54 cm	

* The specifications and pictures are subject to change without notice.