


Test probes

PRUEF 1610 FT Au

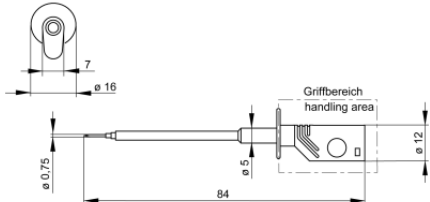

Product	PRUEF 1610 FT Au
description	Safety test probe with shatter-proof insulated sleeve, spring-loaded and slender stainless steel tip. 2 mm diameter gold-plated brass socket connection, stackable with 2 mm safety measuring lead MVL S WS. Oxide layers can be penetrated by this test probe.
operating instruction	BA256
article-no. / *colour	● 00 black ● 01 red Au
drawing	
technical data	
connection	unsprung socket 2 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	10 A
material socket	tip: stainless steel-BR-socket: brass
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022