


Clamp-type test probe

KLEPS 2 BU

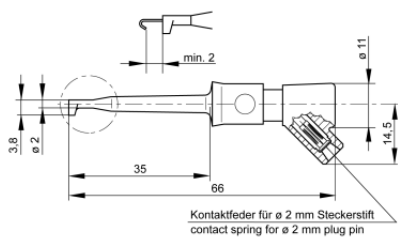

Product	KLEPS 2 BU
description	Miniature clamp-type test probe with 2 mm diameter socket connection. Gold-plated copper beryllium contact spring. Gold-plated sprung bronze contact hook for wires up to a maximum diameter of 2 mm. Suitable for connection to wrap posts up to a maximum of
operating instruction	BA202
article-no. / *colour	9735011xx  00 black  01 red Au
drawing	
	
technical data	
connection	spring loaded socket 2 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
clamp type	contact hook, gold plated

2 mm system

clamping range	max. Ø 2 mm
----------------	-------------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022