




For AMP 1.5 Superseal Terminal
AWG 22-20/16
0.35-0.5/1.5 mm²



For Delphi Weather Pack Terminal (0.35-0.8 mm²)
AWG 22/20-18
0.35/0.5-0.8 mm²



For AMP 1.5 Superseal Terminal
AWG 18/17
0.75/1.0 mm²

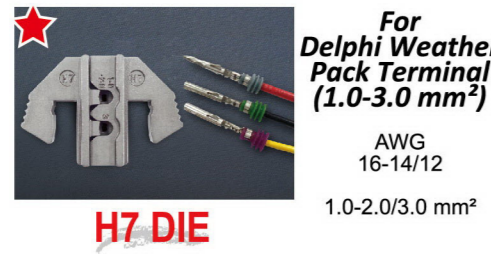

For Delphi Weather Pack Terminal (1.0-3.0 mm²)
AWG 16-14/12
1.0-2.0/3.0 mm²



For Deutsch Terminal
AWG 14/12



For Deutsch Terminal
AWG 20/18/16



For Deutsch Terminal
AWG 10/12
6.0/5.0 mm²



For Deutsch Terminal
AWG 20/18-16




For Deutsch Terminal
AWG 18/16/14



For Deutsch Terminal
AWG 16/14/12



Insulated Terminal
AWG 22-18/16-14/12-10
0.5-1.0/1.5-2.5/4.0-6.0 mm²

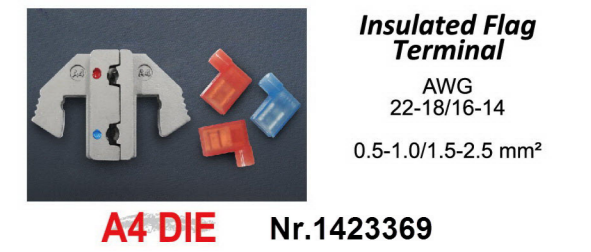

Insulated Flag Terminal
AWG 22-18/16-14
0.5-1.0/1.5-2.5 mm²



Heat Shrink Butt Connector
AWG 22-18/16-14/12-10/8
0.5-1.0/1.5-2.5/4.0-6.0/10 mm²



Closed End Connector & Heat Shrink Terminal
AWG 22-16/16-14/12-10
0.5-1.5/1.5-2.5/4.0-6.0 mm²



Fully Insulated Quick Disconnect
AWG 22-18/16-14/12-10
0.5-1.0/1.5-2.5/4.0-6.0 mm²



Non-Insulated Terminal
AWG 20-18/16-14/12-10/8
1.5/2.5/6.0/10 mm²



Miniature Insulated Terminal
AWG 26-22/24-18/22-16
0.1-0.5/0.25-1.0/0.5-1.5 mm²



Auto. Machine Wiring. Technician. Electrician

Cars, Lorries, Marine, Kit Cars, Buggies, Race/Track Cars, Wiring Looms etc. Boat. VAN. MOTOR. Truck-Headlight.


For Waterproof Terminal

For Deutsch Terminal

Deutsch Series
Steps for choosing Wire, Terminal, Housing and Die Set.

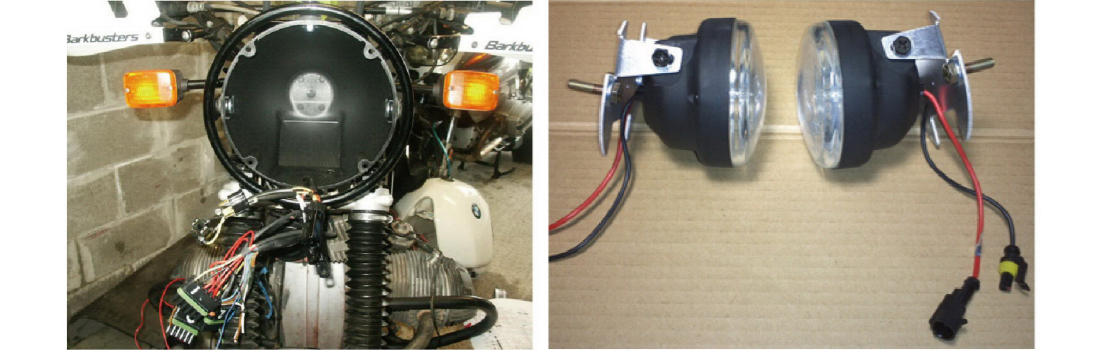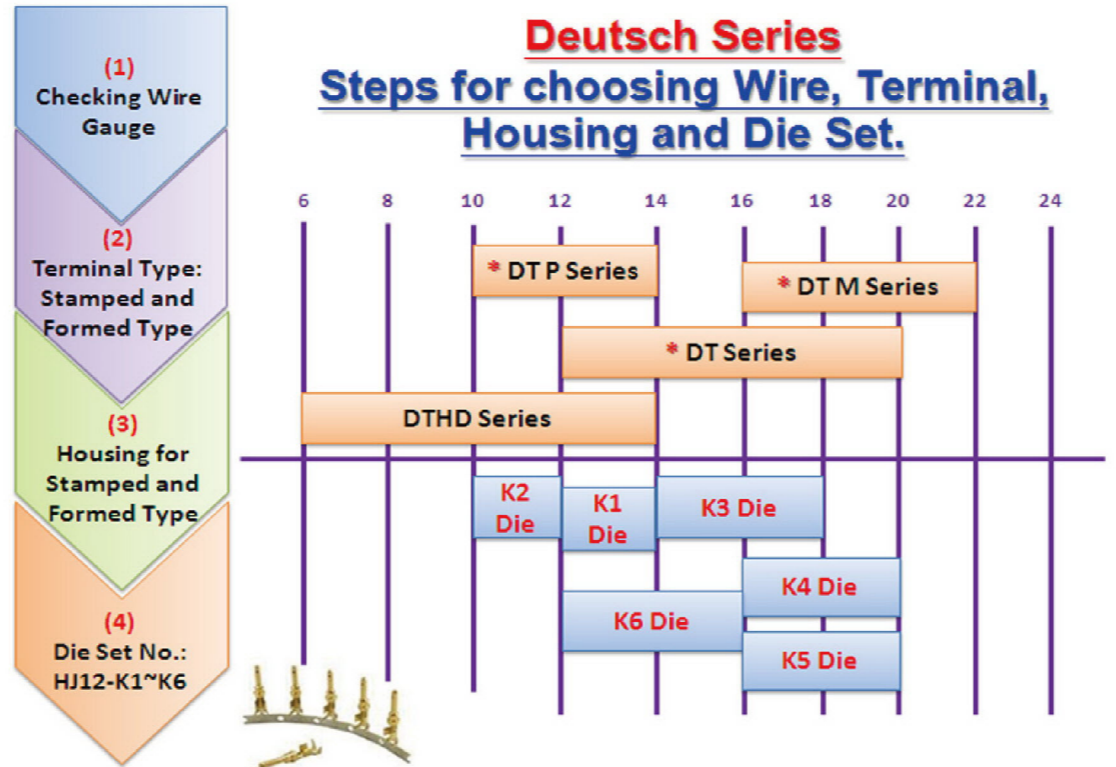

For Insulated Terminal & Non-Insulated Terminal

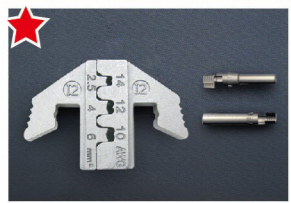

For MC4 Solar Connector
AWG 14/12/10
2.5/4.0/6.0 mm²

I2 DIE



For MC3 Solar Connector
AWG 14/12/10
2.5/4.0/6.0 mm²

IQ1 DIE Nr.405614



For MC4 Solar Connector
AWG 14/12/10
2.5/4.0/6.0 mm²

IQ2 DIE Nr.818646




For Tyco Solar Connector
AWG 15-10
1.5/2.5/4.0/6.0 mm²

IQ3 DIE



RG type Coaxial Cable Connector
.255/.213/.100/.068/.324"
6.48/5.41/2.54/1.72/8.23 mm
RG 58, 59, 62, 6

E DIE Nr.1423396

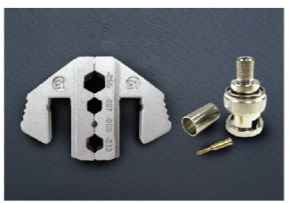


RG type Coaxial Cable Connector
.255/.187/.068/.213"
6.48/4.75/1.72/5.41 mm
RG 58, 59, 62, 174

E1 DIE Nr.1423397




RG type Coaxial Cable Connector
.256/.319/.068/.213"
6.50/8.10/1.72/5.41 mm
RG 58, 59, 62, 6

E2 DIE Nr.1423398

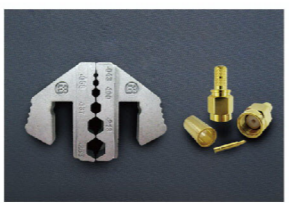

RG type Coaxial Cable Connector
.043/.068/.100/.137/.213/.255"
1.09/1.72/2.54/3.48/5.41/6.48 mm
RG 58, 59, 62, 174
Fiber Optic

E3 DIE Nr.1423399

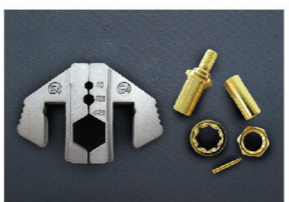

RG type Coaxial Cable Connector
.100/.128/.429"
2.54/3.25/10.9 mm
RG 8, 11, 174, 179, 213

E4 DIE Nr.1423400



RG type Coaxial Cable Connector
.042/.068/.078/.128/.151/.178"
1.07/1.72/1.98/3.25/3.84/4.52 mm
RG 174, 179 Belden
8218 Fiber Optic

E5 DIE Nr.1423401



RG type Coaxial Cable Connector
.100/.213/.319/.360"
2.54/5.41/8.10/9.14 mm
RG 58, 59, 6

E6 DIE Nr.1423402



4P4C Connector
4P4C/RJ22 Plugs

G1 DIE



6P6C Connector
6P2C, 6P4C/RJ11 Plugs
6P6C/RJ12 Plugs

G2 DIE



8P8C Connector
8P8C/RJ45 Plugs

G3 DIE



Computer, ADSL.




Fax machine, Printer

Telephone



Open Barrel Terminal
AWG 20-18/16-14/12-10
0.5-1.0/1.5-2.5/
4.0-6.0 mm²

C DIE Nr.1423380

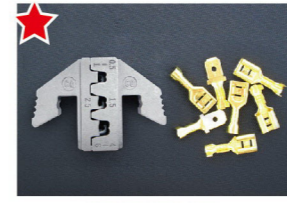


Open Barrel Terminal
AWG 20-18/16-14/12-10
0.5-1.0/1.5-2.5/
4.0-6.0 mm²

CQ DIE




Open Barrel Terminal
AWG 26-24/24-22/22-18
0.1-0.25/0.25-0.5/
0.5-1.0 mm²

C1 DIE Nr.1423390

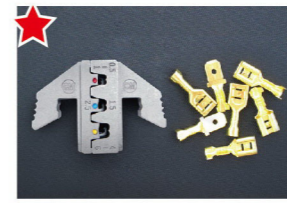

Open Barrel Terminal
AWG 20-18/16-14/12-10
0.5-1.0/1.5-2.5/
4.0-6.0 mm²

CM DIE

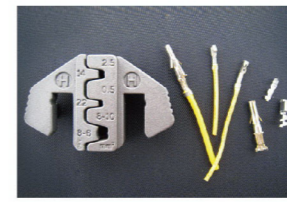

Open Barrel Terminal & D-Sub, V3.5
AWG 14/22/8-6
2.5/0.5/8.0-10 mm²

H DIE Nr.1423407



Spark Plug Connector
AWG 17
1.0 mm²

H1 DIE Nr.1423409



Cord End Terminal
AWG 22/20/18/
16/14/12
0.5/0.75/1.0/
1.5/2.5/4.0 mm²

D DIE Nr.1423395





Cord End Terminal
AWG 10/8/6
6.0/10/16 mm²

F DIE Nr.1423403



Cord End Terminal
AWG 4/2
25/35 mm²

F1 DIE

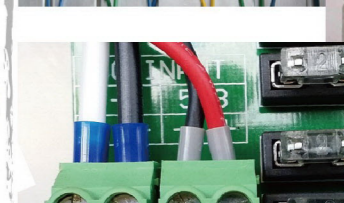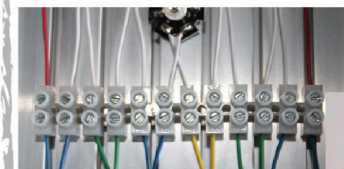

Auto. Machine Wiring. Electrical Engineer

For BNC Connector & For Modular Connector

For Open Barrel Terminal & For Cord End Terminal



★ Designed by Germany. Made in Taiwan.

For Solar Connector