

# Programming Quick Guide

## FS5020E

### Installation

Make sure that the scanner has the correct cable to plug in the PC as below described::

#### Reset Configuration to Defaults

If you are unsure of the scanner configuration or have scanned the incorrect codes, please scan the “Default” barcode. This will reset the scanner to its factory defaults.




Default

\*Please remove the protective sticker from window before use.



Do not read barcode at vertical degree.

In order scanner to decode properly, please make sure relocation the barcode from scanner window completely when reading same barcode.

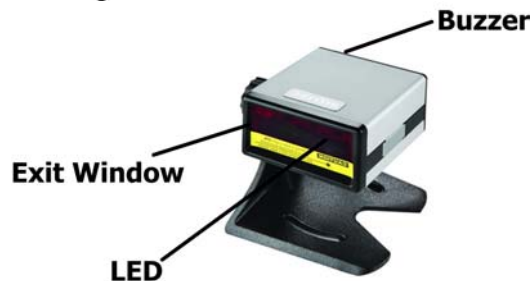


- If you want expand laser timeout, please scan “Single Scan No Trigger + Laser Timeout-x seconds”.



- This is used for determining if need to repeat the reading and decoding after successfully reading barcodes.

#### READING MODE

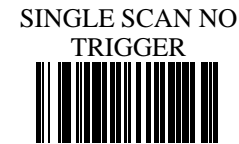

#### DOUBLE CHECK



 
#### I2OF5 DOUBLE CHECK - ENABLE



#### ID2OF5 DOUBLE CHECK - ENABLE




#### MSI DOUBLE CHECK - ENABLE



#### UPC/EAN DOUBLE CHECK ENABLE


 
#### REVERSE IMAGE - ENABLE



#### SEND BAR CODE ID - DISABLE



#### SEND BAR CODE ID - RESET



- to check the symbology of barcode you scan (g means Code 128; e means EAN 13)

#### DOUBLE CHECK

#### I2OF5 DOUBLE CHECK - DISABLE



#### ID2OF5 DOUBLE CHECK - DISABLE



 
#### MSI DOUBLE CHECK - DISABLE



#### UPC/EAN DOUBLE CHECK DISABLE



#### REVERSE IMAGE - DISABLE



#### SEND BAR CODE ID - AS A PREFIX



#### SEND BAR CODE ID - AS A SUFFIX



## Keyboard Language

Scan the appropriate country code below to program the keyboard for your country or language. As a general rule, the following characters are not supported by the scanner for countries other than the United States: @ | \$ # { } [ ] = / ' \ < > ~

 
DENMARK




FINLAND




FRANCE



GERMANY

 


ITALY

 


LATIN AMERICA



 
NETHERLANDS




NORWAY

 


POLAND

 


SPAIN

 


SWITZERLAND  
(FRENCH)

 


SWITZERLAND  
(GERMAN)

 

SWEDEN

 


UNITED KINGDOM

 

UNIVERSAL



 UNITED STATES



## Symbologies On/OFF-1

CODE 11 –  
ENABLE




CODE 11

CODE 11 –  
DISABLE



 CODE 39 –  
ENABLE



CODE 39


CODE 39 –  
DISABLE




FULL ASCII –  
ENABLE



 FULL ASCII –  
DISABLE



CODE 93  
-ENABLE

 


CODE 93

CODE 93  
-DISABLE




 CODE 128  
-ENABLE



CODE 128

 
CODE 128 –  
DISABLE




CODE 128 ISBT –  
ENABLE



 CODE 128 ISBT –  
DISABLE



CODABAR –  
ENABLE

 

CODABAR

CODABAR –  
DISABLE



## Symbologies On/OFF-2

I2OF5 - ENABLE



INTERLEA  
VED 2 OF 5

I2OF5 - DISABLE

 


ID2OF5 - ENABLE



INDUSTRIAL  
2 OF 5

ID2OF5 - DISABLE



MSI - ENABLE

 


MSI

MSI - DISABLE




UPC-A ENABLE




UPC/EAN

 
UPC-A DISABLE



UPC-E ENABLE

 


UPC-E DISABLE

 

EAN-13 ENABLE



 EAN-13 DISABLE



EAN-8 ENABLE



EAN-8 DISABLE

