


## QVGA Camera Cable

Item no: 409211

### Overview

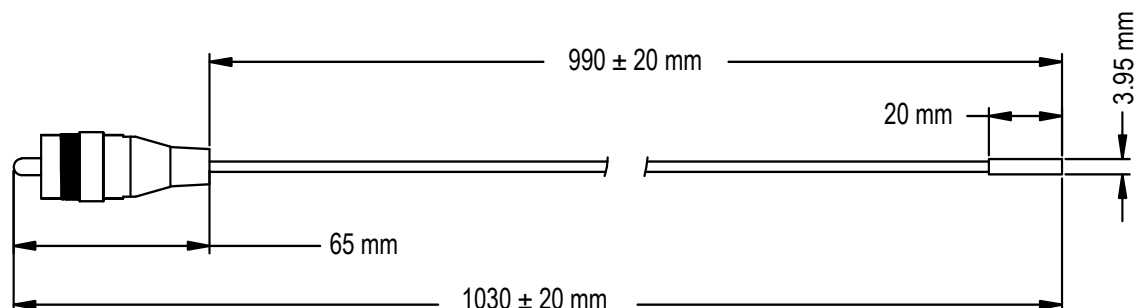

### Technical data

TV system.....	NTSC
Image device .....	1/18"
Effective picture element .....	320 (H) x 240 (V)
Scanning system .....	2:1 Interlace
Sync system .....	Internal
Resolution.....	200 TV Lines
S/N ratio.....	> 48 dB
Minimum illuminance .....	>0 lux
AGC.....	On
AES .....	1/60 - 1/170000 s
Gamma correction .....	0.45
Field of view.....	54°
Focus range.....	10 – 50 mm
Light source .....	4x high luminous white color LED
LED lux.....	max. 600 +/- 150 lux by 20 mm
Power consumption .....	approx. 0.35 W
Operating temperature .....	0 to +45°C
Operating humidity .....	15 – 85 % RH
Storage temperature.....	-10 to +50°C
Storage humidity.....	15 – 85 % RH
Total length of device .....	103 +/- 2 cm
Gooseneck length.....	97 +/- 2 cm
Bending radius.....	min. 45 mm
Weight (N.W).....	approx. 50 g