

**06 H**

Fig. 1

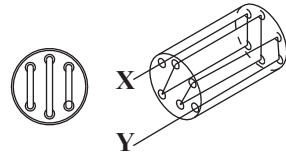
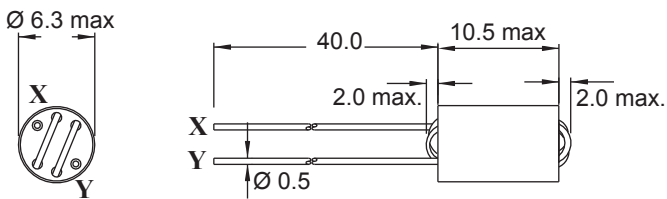


Fig. 2

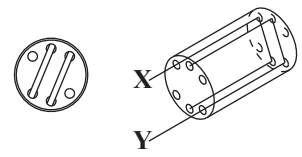
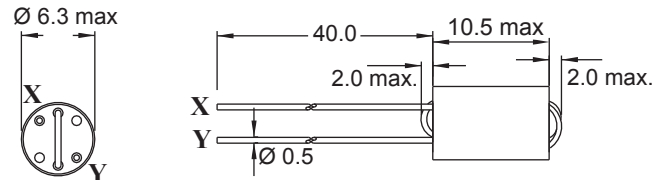


Fig. 3

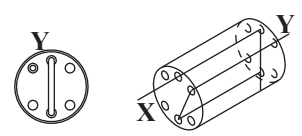
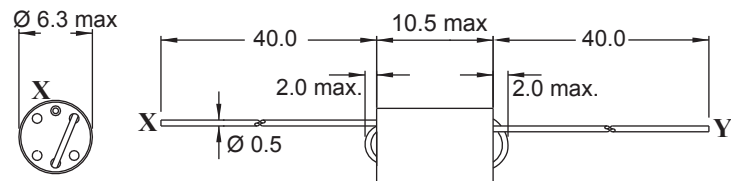


Fig. 4




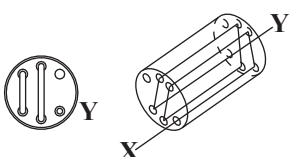


Fig. 5

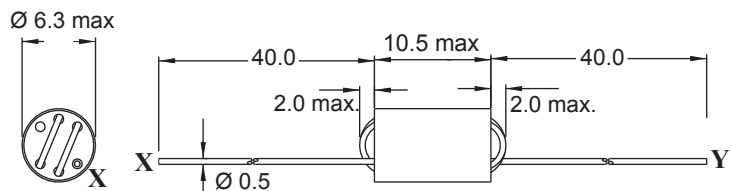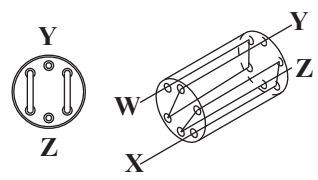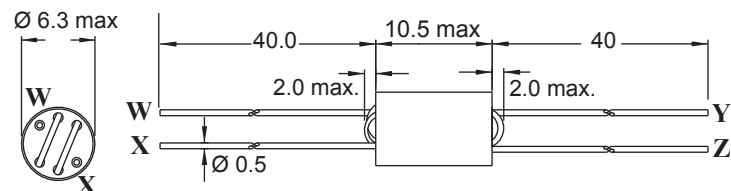

All dimensions in mm

Wide Band Chokes


**SPQ :**

Part No	Impedance Z min(Ω)	fz (MHz)	Turns	Current (A)	Fig.	Packing Form (Axial) Loose / Box
06H-351X-00	300	120	1½	1.0	3	600
06H-451X-00	350	250	1½	1.0	3	600
06H-551X-50	800	50	3	1.0	1	500
06H-651X-50	520	50	2	1.0	2	500
06H-751X-00	600	50	2½	1.0	4	600
06H-851X-00	700	180	2½	1.0	4	600
06H-901X-00	700	50	2 x 1½	1.0	5	400
06H-102X-00	800	110	2 x 1½	1.0	5	400
06H-881X-50	750	180	3	1.0	1	500


**Material :** Ferrite

**Remark :** All models are available with insulation tube (06 H/T)


Typical IZI vs Frequency (f)

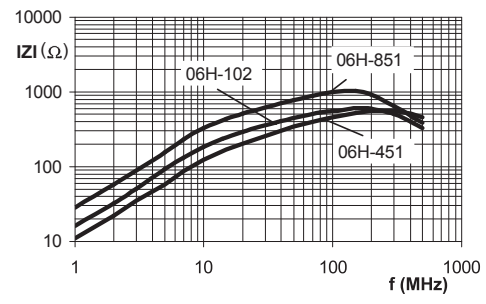

Typical a(dB) vs Frequency (f)

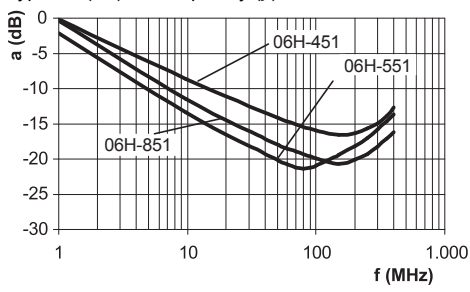

Typical a(dB) vs Frequency (f)

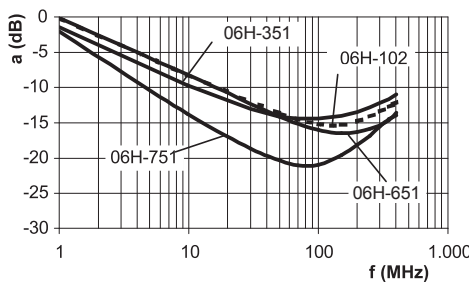

Typical IZI vs Frequency (f)

