
 
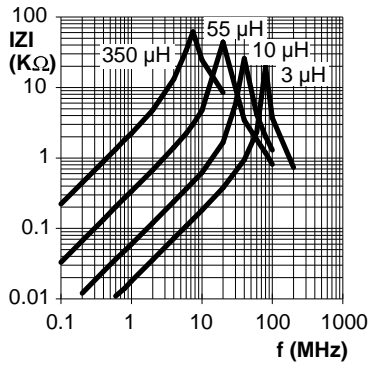


Suppression Coils




Series

ME**D**ium S**U**ppression C**O**il **MESC**

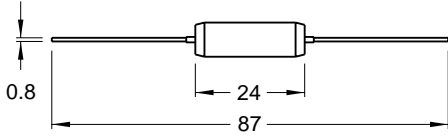

| Ordering Code | Inductance L (μH) | f _L (MHz) | Tol. % | Current (A) | Resistance (mΩ) | Material |
|---------------|----------------------|-------------------------|-----------|----------------|--------------------|------------|
| MESC-3R0M-01 | 3 | 1.00 | ± 20 | 6.00 | 22 | Iron Oxide |
| MESC-5R0M-01 | 5 | | | 4.00 | 41 | |
| MESC-100M-01 | 10 | 0.10 | ± 20 | 3.00 | 105 | |
| MESC-150M-01 | 15 | | | 2.00 | 198 | |
| MESC-250M-01 | 25 | 0.10 | ± 20 | 1.50 | 468 | |
| MESC-550M-01 | 55 | | | 0.70 | 1560 | |
| MESC-131M-01 | 130 | 0.10 | ± 20 | 0.40 | 5760 | |
| MESC-161M-01 | 160 | | | 0.30 | 7920 | |
| MESC-351M-01 | 350 | 0.15 | 0.15 | 25200 | | |

Option without insulating material protection (MESC/B)

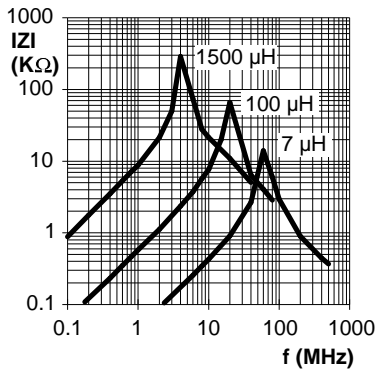

| Ordering Code | Inductance L (μH) | f _L (MHz) | Tol. % | Current (A) | Resistance (mΩ) | Material |
|---------------|----------------------|-------------------------|-----------|----------------|--------------------|----------|
| MESC-7R0M-01 | 7 | 1.0 | ± 20 | 6.00 | 24 | Ferrite |
| MESC-120M-01 | 12 | 0.10 | | 4.00 | 48 | |
| MESC-220M-01 | 22 | | 0.10 | 3.00 | 84 | |
| MESC-400M-01 | 40 | 0.10 | | 2.00 | 216 | |
| MESC-560M-01 | 56 | | 0.10 | 1.50 | 360 | |
| MESC-101M-01 | 100 | 0.10 | | 1.00 | 780 | |
| MESC-221M-01 | 220 | | 0.10 | 0.50 | 3120 | |
| MESC-471M-01 | 470 | 0.10 | | 0.30 | 7800 | |
| MESC-681M-01 | 680 | | 0.10 | 0.20 | 16800 | |
| MESC-122M-01 | 1200 | 0.01 | | 0.10 | 40800 | |
| MESC-152M-01 | 1500 | | 0.08 | 0.08 | 64800 | |

Option without insulating material protection (MESC/B)