


O6353

CABLE ASSEMBLY, FIBER OPTIC, 50/125 μ m,
OM2 (infinicor 600) MINI ZIPCORD, SC TO ST

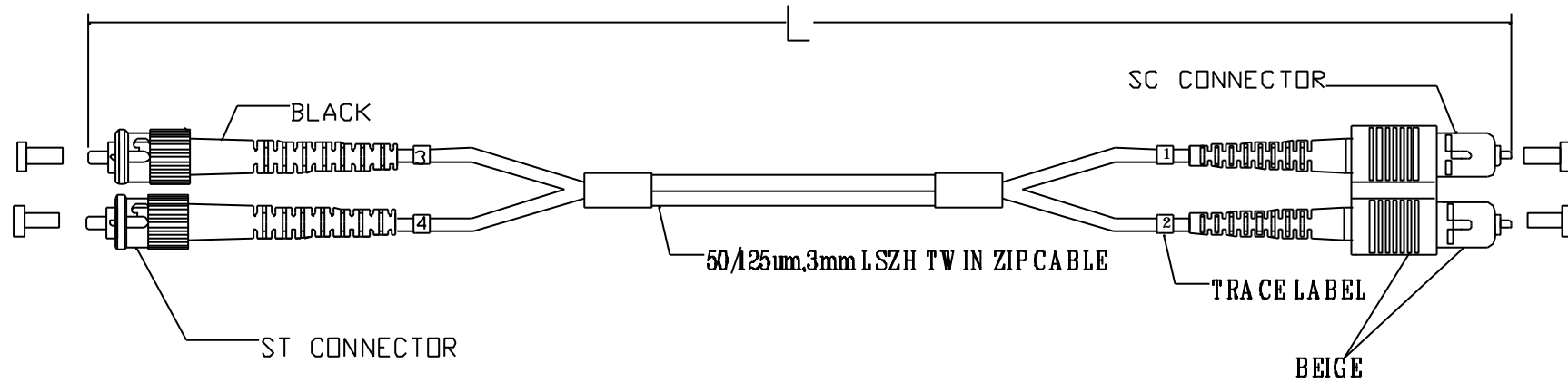

1. SC connectors meets TIA/EIA-604-3 & ST connectors meets TIA/EIA-604-2
2. Fiber Optic Cable Performance Properties
 - § Comply with TIA/EIA-568 B.3 & Bellcore GR-409-CORE & OFNR-UL/CSA FT-4
 - § Maximum Attenuation : ☞ 3.0dB/km @ 850nm
☞ 1.0dB/km @ 1300nm
 - § Minimum Bandwidth : ■ 400MHz-Km @ 850nm
■ 500MHz-Km @ 1300nm
3. SC & ST Specification
 - § Durability: 500 matings
 - § Operating Temperature: -40 to +80
 - § Insertion Loss: Typical < 0.2dB, Maximum < 0.3dB
 - § Cable Retention: > 11 lbs. /50 N straight, > 4 lbs. / 19 N at 90°
 - § Color: SC Beige ST Black
4. Ordering Information
 SC/ST50Z ☞ ☞ ☞ P
 ☞ ☞
- ☞ Outer Jacket
 P-PVC
 L-LSZH
- ☞ Length, in meters
5. Packing
 The corresponding label data for each cable assembly shall be glued to the package

Item	SC-ST 2M (50/125) MM			
Item No.	SC/ST50ZL02P			
Insertion Loss	1	2	3	4
	0.10dB	0.14dB	0.25dB	0.13dB
Date	2003.01.10			