

ALPHASTAT 16

Ausführung MONO/single turn

Typ 63250-014XX


Welle/shaft 4 mm L=30 mm

Buchse/bushing M7x0,75





Printausführung/for printed circuit

Drehbereich/Rotation angle 270° +-5%

Belastbarkeit/rated wattage lin 0,2W/log 0,05 W

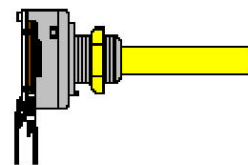

63250-014XX

 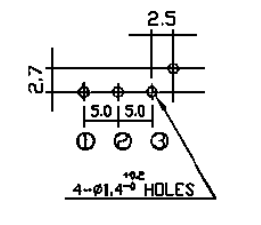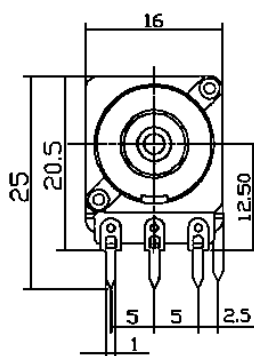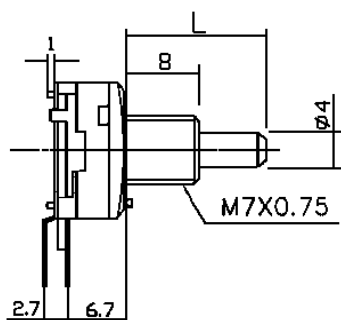

| | Standard 63250-01400/— | | Mittenrast/center click 63250-01410/— | Rast 11/11 clicks 63250-01420/— | Rast 41/41 clicks 63250-01440/— |
|--------------|---------------------------|--------|--|------------------------------------|------------------------------------|
| | lin | poslog | neglog | | |
| 1 k | 449803 | 449842 | | | |
| 2,5 k | | | | | |
| 5 k | | | | | |
| 10 k | 449816 | 449855 | | | |
| 25 k | | | | | |
| 50 k | | | | | |
| 100 k | 449829 | 449869 | | | |
| 250 k | | | | | |
| 500 k | | | | | |
| 1 M | | | | | |

lagermassige Ausführungen