

ALPHASTAT 16

Ausführung MONO/single turn

Typ 63250-014XX


Welle/shaft 4 mm L=30 mm

Buchse/bushing M7x0,75





Printausführung/for printed circuit

Drehbereich/Rotation angle 270° +-5%

Belastbarkeit/rated wattage lin 0,2W/log 0,05 W

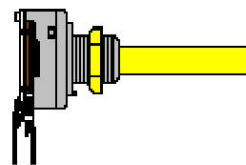

63250-014XX

 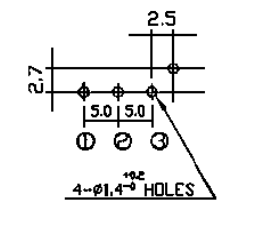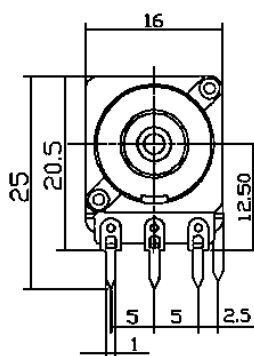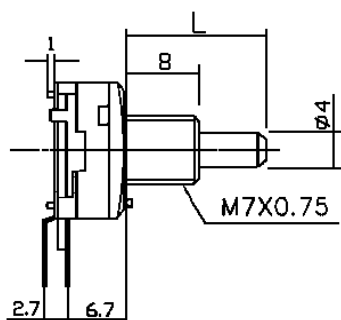

	Standard 63250-01400/—		Mittenrast/center click 63250-01410/—	Rast 11/11 clicks 63250-01420/—	Rast 41/41 clicks 63250-01440/—
	lin	poslog	neglog		
1 k	449803	449842			
2,5 k					
5 k					
10 k	449816	449855			
25 k					
50 k					
100 k	449829	449869			
250 k					
500 k					
1 M					

lagermassige Ausführungen