

# ALPHASTAT 16

Ausführung MONO mit Tragkäfig/single turn with bracket

Typ 63250-214XX


Welle/shaft 4 mm L=30 mm

Buchse/bushing M7x0,75





Printausführung/for printed circuit

Drehbereich/Rotation angle 270° +-5%

Belastbarkeit/rated wattage lin 0,2W/log 0,05 W

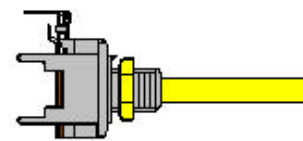

63250-214XX

 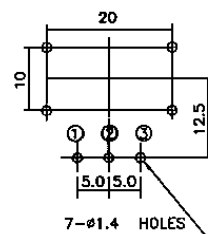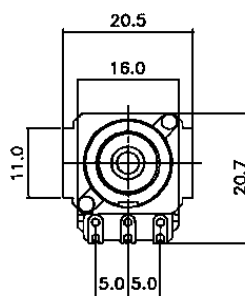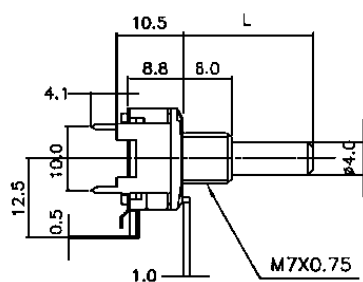

	Standard 63250-21400/—			Mittenrast/center click 63250-21410/—			Rast 11/11 clicks 63250-21420/—			Rast 41/41 clicks 63250-21440/—		
	lin	poslog	neglog	lin	poslog	neglog	lin	poslog	neglog	lin	poslog	neglog
<b>1 k</b>	449883											
<b>2,5 k</b>												
<b>5 k</b>												
<b>10 k</b>	449896											
<b>25 k</b>												
<b>50 k</b>												
<b>100 k</b>	449909											
<b>250 k</b>												
<b>500 k</b>												
<b>1 M</b>												

lagermässige Ausführungen