


KEMET Part Number: PMR209MC6220M100R30
(P409CP224M250AH101)

Capacitor, film, 0.22 uF, +/-20% Tol, -40/+85C, Capacitor with Integrated Resistor (Safety: X2), 630V@85C, Lead Spacing=20.3 mm

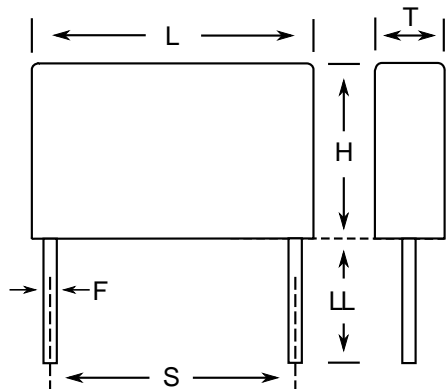

Dimensions (mm)		
Symbol	Dimension	Tolerance
L	24	Max
H	16.5	Max
T	11.3	Max
S	20.3	+/-0.4
LL	30	+5
F	0.8	+/-0.05

Packaging Specifications	
Package Kind:	Bulk
Package Quantity:	150

General Information	
Manufacturer:	KEMET
Miscellaneous Electrical:	Resistor tol: +/-30%

Specifications	
Capacitance:	0.22 uF
Rated Temperature:	85C
Voltage @ rated temp:	630V
Voltage AC:	250VAC
Tolerance:	+/-20%
Body Type:	Radial Molded
Dielectric:	Metallized Paper
Construction:	Wound
Application:	Capacitor with Integrated Resistor (Safety: X2)
Temperature Range:	-40/+85C
Electrical Name (Other):	Resistor
Electrical Value (Other):	100
Electrical Units (Other):	Ohms
Insulation Resistance:	3 GOhm

Agency Approvals	
UL_1414:	250V
IEC_60384-14:	250V
EN_132400:	250V