


MH-4 TYPE

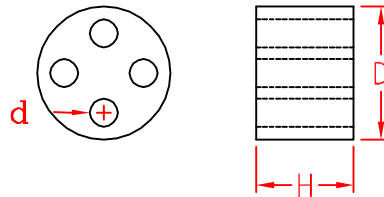

| ITEM NO. | D | d | H |
|----------|----------|----------|-----------|
| MH9-4A | 9±0.5 | 2.3±0.25 | 7.3±0.25 |
| MH11-4A | 11±0.5 | 2.3±0.25 | 8.0±0.25 |
| MH14-4A | 14±0.5 | 2.3±0.25 | 9.2±0.25 |
| MH14-4B | 14±0.5 | 2.4±0.25 | 9.2±0.25 |
| MH14-4C | 14±0.5 | 3.4±0.25 | 9.2±0.25 |
| MH16-4A | 16±0.5 | 4.0±0.25 | 8.4±0.25 |
| MH18-4A | 17.5±0.5 | 2.4±0.25 | 9.0±0.25 |
| MH18-4B | 17.5±0.5 | 2.5±0.25 | 9.0±0.25 |
| MH18-4C | 17.5±0.5 | 3.4±0.25 | 9.0±0.25 |
| MH18-4D | 17.5±0.5 | 3.6±0.25 | 9.0±0.25 |
| MH18-4E | 17.5±0.5 | 4.2±0.25 | 9.0±0.25 |
| MH18-4F | 17.5±0.5 | 4.8±0.25 | 9.0±0.25 |
| MH23-4A | 22.8±0.5 | 2.5±0.25 | 11.2±0.35 |
| MH23-4B | 22.8±0.5 | 3.1±0.25 | 11.2±0.35 |
| MH23-4C | 22.8±0.5 | 3.6±0.25 | 11.2±0.35 |
| MH23-4D | 22.8±0.5 | 4.1±0.25 | 11.2±0.35 |
| MH23-4E | 22.8±0.5 | 4.8±0.25 | 11.2±0.35 |
| MH23-4F | 22.8±0.5 | 5.2±0.25 | 11.2±0.35 |
| MH23-4G | 22.8±0.5 | 7.3±0.25 | 11.2±0.35 |
| MH30-4A | 30.4±1.0 | 3.1±0.25 | 14.4±0.35 |
| MH30-4B | 30.4±1.0 | 4.1±0.25 | 14.4±0.35 |
| MH30-4C | 30.4±1.0 | 5.2±0.25 | 14.4±0.35 |
| MH30-4D | 30.4±1.0 | 7.3±0.25 | 14.4±0.35 |
| MH30-4E | 30.4±1.0 | 9.0±0.25 | 14.4±0.35 |
| MH39-4A | 39.0±1.0 | 12±0.35 | 17.3±0.35 |
| MH42-4A | 41.8±1.0 | 12±0.35 | 17.0±0.35 |

| | | | |
|-----------|------------------------|----------------------|-----------------------------------|
| | | MATERIAL | ITEM NO. |
| | | TPE | MH-4 TYPE |
| SCALE | | FINISH | NAME Multi-Hole Seal (4 HOLES) |
| △ (. .) | TOLERANCE AS FIGURE | △ 04-20-2012 DATE | REVISIONS K001 |
| | | | R.NO. |

