


Artikel-Nr.: 457780


Bez.: Power Stecker 3 polig

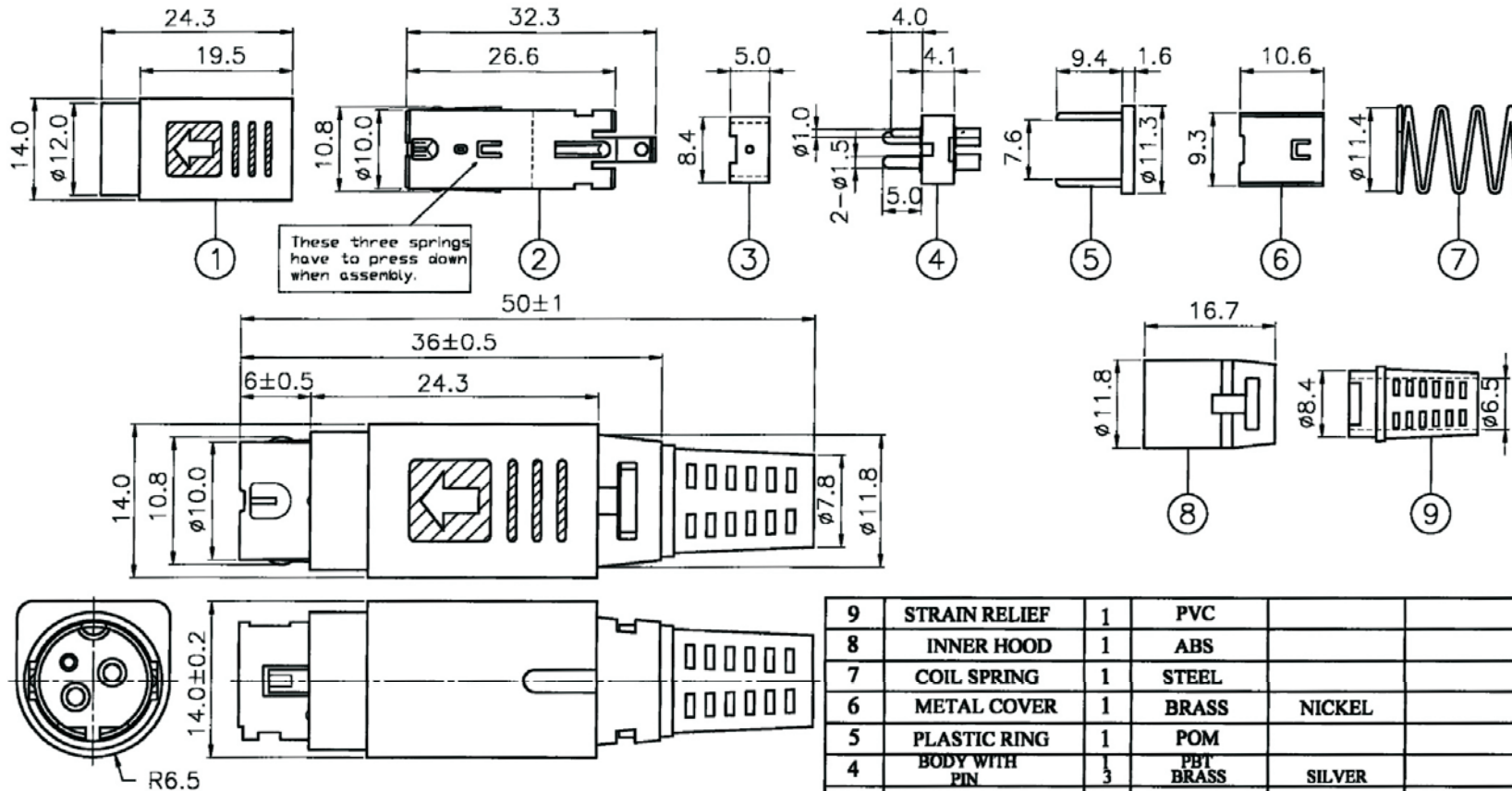

SPECIFICATIONS:

1. RATING : PIN A&B : 20V DC 7.5A MAX. (PIN DIA. 1.5 ϕ)
PIN C : 20V DC 1A MAX. (PIN DIA. 1.0 ϕ)
2. INSULATION RESISTANCE : 50M OHM MIN. AT 250V DC.
3. DIELECTRIC STRENGTH : 250V AC / 1 MINUTE.

***Unless other specified, the tolerance is $\pm 0.2\text{mm}$

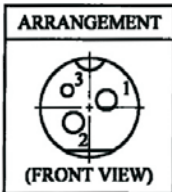

9	STRAIN RELIEF	1	PVC		
8	INNER HOOD	1	ABS		
7	COIL SPRING	1	STEEL		
6	METAL COVER	1	BRASS	NICKEL	
5	PLASTIC RING	1	POM		
4	BODY WITH PIN	3	PBT BRASS	SILVER	
3	CLAMP	1	BRASS	NICKEL	
2	METAL SLEEVE	1	BRASS	NICKEL	
1	OUTER HOOD	1	ABS		
P/N	PART NAME	Q'TY	MATERIAL	PLATING	REMARKS

www.bkl-electronic.de

Technische Änderungen vorbehalten. Ausführungen können variieren. Sollten Sie ein Muster benötigen kontaktieren Sie uns bitte.

BKL-ELECTRONIC Kreimendahl GmbH • Märkenstück 14 • 58509 Lüdenscheid
Tel: +49 (0)2351-3621-0 • Fax: +49 (0)2351-3621-29 • info@bkl-electronic.de

