


C0603C180J5GACTU

aka C0603C180J5GAC7867

Capacitor, ceramic, 18 pF, +/-5% Tol, 50V, C0G, 0603

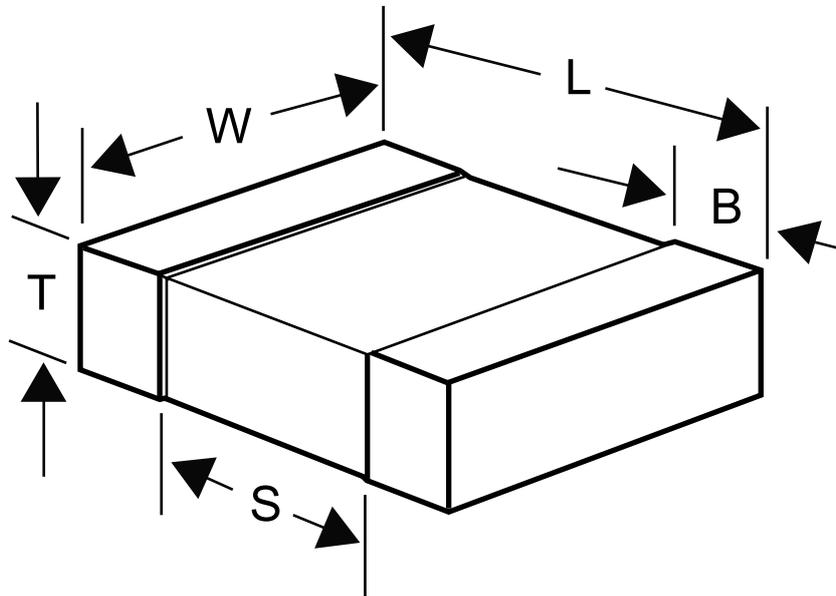

Dimensions (mm)

Specifications

ID	Dimension	Tolerance
L	1.60	+/-0.15
W	0.80	+/-0.15
T	0.8	+/-0.07
B	.35	+/-0.15
S	0.7	min

Manufacturer:	KEMET
Capacitance:	18 pF
Chip Size:	0603
Voltage:	50V
Temperature Coefficient:	C0G
Tolerance:	+/-5%
Application:	Std Chip
Termination Type:	Tin
Marked:	No
Dissipation Factor:	0.1%
Insulation Resistance:	100 GOhm
Dielectric Strength:	125V
Package Kind:	T&R
Package Size:	7in
Package Type:	Paper Tape
Package Quantity:	4000