


# C0603C479C5GACTU

aka C0603C479C5GAC7867

Capacitor, ceramic, 4.7 pF, +/-0.25pF Tol, 50V, C0G, 0603

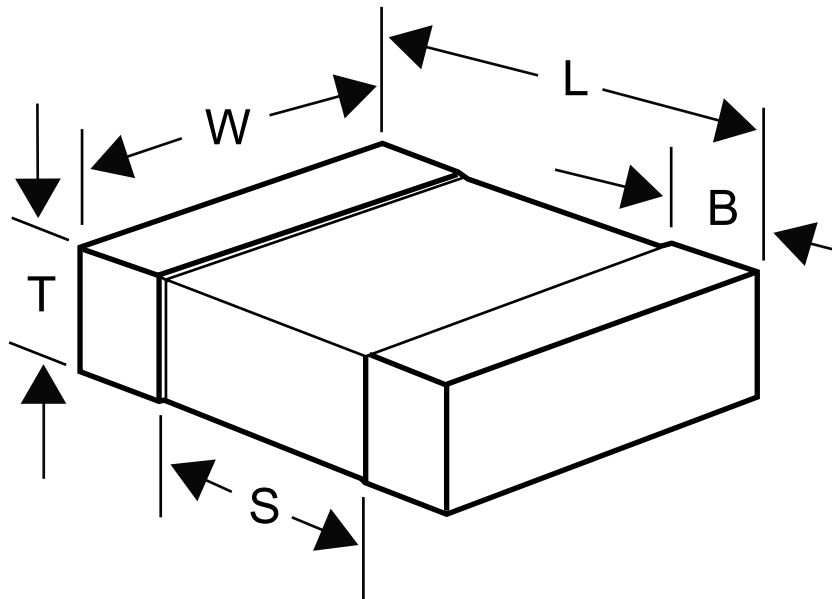

## Dimensions (mm)

## Specifications

ID	Dimension	Tolerance	Manufacturer:	KEMET
L	1.60	+/-0.15	Capacitance:	4.7 pF
W	0.80	+/-0.15	Chip Size:	0603
T	0.8	+/-0.07	Voltage:	50V
B	.35	+/-0.15	Temperature Coefficient:	C0G
S	0.7	min	Tolerance:	+/-0.25pF
			Application:	Std Chip
			Termination Type:	Tin
			Marked:	No
			Dissipation Factor:	0.1%
			Insulation Resistance:	100 GOhm
			Dielectric Strength:	125V
			Package Kind:	T&R
			Package Size:	7in
			Package Type:	Paper Tape
			Package Quantity:	4000