


C0805C474K3RACTU

aka C0805C474K3RAC7867

Capacitor, ceramic, 0.47 uF, +/-10% Tol, 25V, X7R, 0805

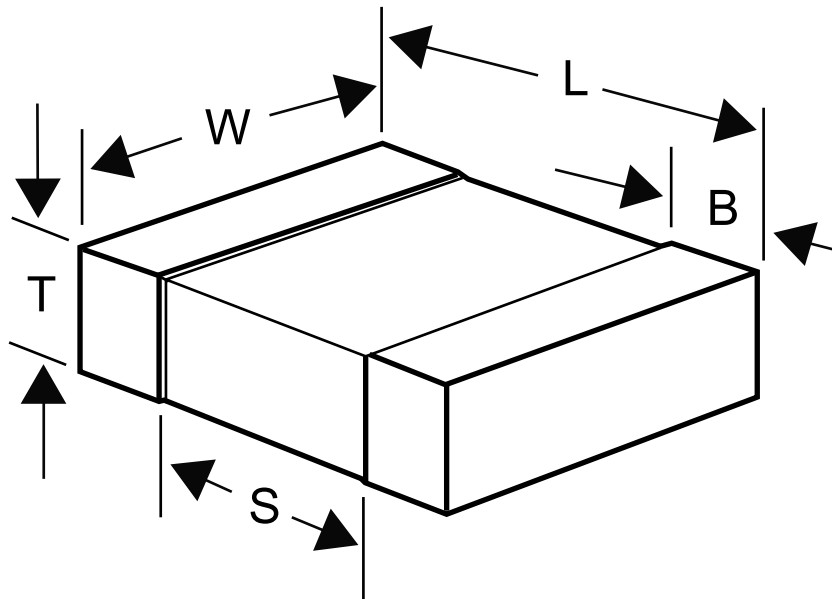

Dimensions (mm)

Specifications

ID	Dimension	Tolerance	Manufacturer:	KEMET
L	2.00	+/-0.20	Capacitance:	0.47 uF
W	1.25	+/-0.20	Chip Size:	0805
T	0.9	+/-0.1	Voltage:	25V
B	0.50	+/-0.25	Temperature Coefficient:	X7R
S	0.75	min	Tolerance:	+/-10%
			Application:	Std Chip
			Termination Type:	Tin
			Marked:	No
			Dissipation Factor:	3.5%
			Insulation Resistance:	1.06 GOhm
			Dielectric Strength:	62.5V
			Package Kind:	T&R
			Package Size:	7in
			Package Type:	Paper Tape
			Package Quantity:	4000