


C1206C106K3PACTU

aka C1206C106K3PAC7800

Capacitor, ceramic, 10 uF, +/-10% Tol, 25V, X5R, 1206

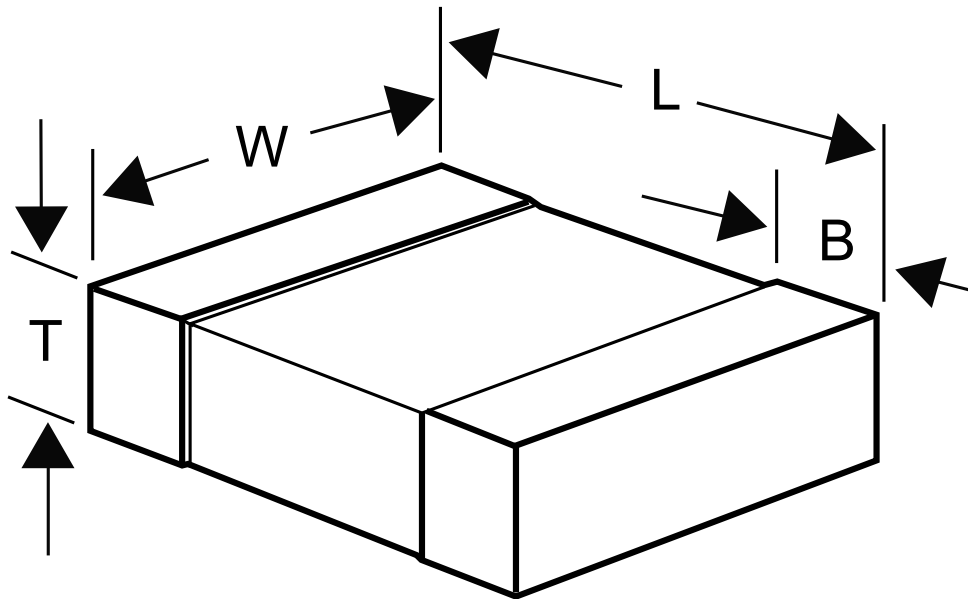

Dimensions (mm)

Specifications

ID	Dimension	Tolerance
L	3.20	+/-0.20
W	1.60	+/-0.20
T	1.6	+/-0.2
B	0.50	+/-0.25

Manufacturer:	KEMET
Capacitance:	10 uF
Chip Size:	1206
Voltage:	25V
Temperature Coefficient:	X5R
Tolerance:	+/-10%
Application:	Std Chip
Termination Type:	Tin
Marked:	No
Dissipation Factor:	5%
Insulation Resistance:	50 MOhm
Dielectric Strength:	62.5V
Package Kind:	T&R
Package Size:	7in
Package Type:	Plastic Tape
Package Quantity:	2000