

Cable housing - KGG-PC 4/ 3-F - 1837324

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Cable housing, Pitch: 0 mm, Number of positions: 3, Dimension a: 24.66 mm, Color: green

Product Features

- Ergonomic cable housing for standard PC 4 plugs with screw connection
- KGS-PC 4 (angled cable outlet) for cable diameters from 6 to 16 mm²
- KGG-PC 4 for cable diameters from 4 to 13.5 mm²
- A cable clamp can be mounted back to front

Key commercial data

package_quantity	10
GTIN	4017918111335

Technical data

Dimensions

Pitch	0 mm
Dimension a	24.66 mm

General

Range of articles	KGG-PC 4/...F
Insulating material group	0
Insulating material	ABS
Inflammability class according to UL 94	HB
Number of positions	3

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402
eCl@ss 8.0	27440402

Cable housing - KGG-PC 4/ 3-F - 1837324

classifications

ETIM

ETIM 3.0	EC000058
ETIM 4.0	EC000437
ETIM 5.0	EC000451



UNSPSC

UNSPSC 6.01	30211810
UNSPSC 7.0901	39121409
UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	39121409

approvals

GOST / GOST /

  Approval details



accessories

Terminal marking


SBS 2,5/7,5 - 1007604



Cable housing - KGG-PC 4/ 3-F - 1837324

accessories

KGS-MSTB 2,5/ DST - 1784914

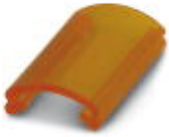

Drawings

Dimensioned drawing

