


Capacitor, tantalum, 2.2 uF, +/-10% Tol, 25V@85C, Lead Spacing=2.54 mm

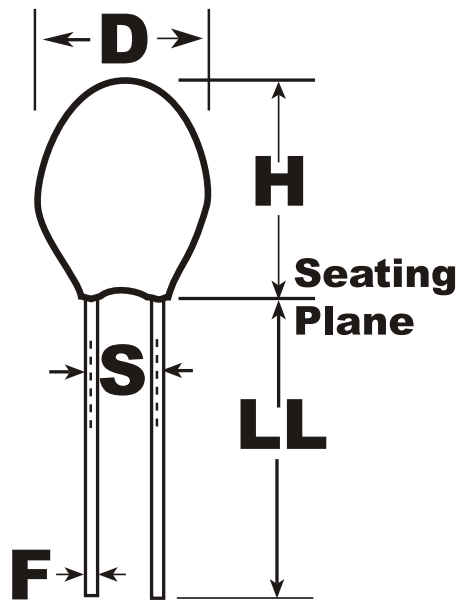

Dimensions (mm)

Specifications

ID	Dimension	Tolerance	Manufacturer:	KEMET
D	4.5	+0	Value:	2.2 uF
H	7.6	+0	Voltage DC @ 85C:	25V
F	0.5	+/-0.05	Voltage DC @ 125C:	16.5V
S	2.54	+/-0.38	Tolerance:	+/-10%
LL	12.7	+/-1.26	Body Type:	Radial Conformal ('dipped')
			Temperature Range:	-55/+125C
			Application:	General Purpose
			Termination Type:	Tin
			Leakage Current:	0.5 uA
			Dissipation Factor:	5%
			Package Kind:	Bulk
			Package Type:	Bag