


C320C334M5U5TA

aka C320C334M5U5TA

Capacitor, ceramic, 0.33 uF, +/-20% Tol, 50V, Z5U, Lead Spacing=0.1"

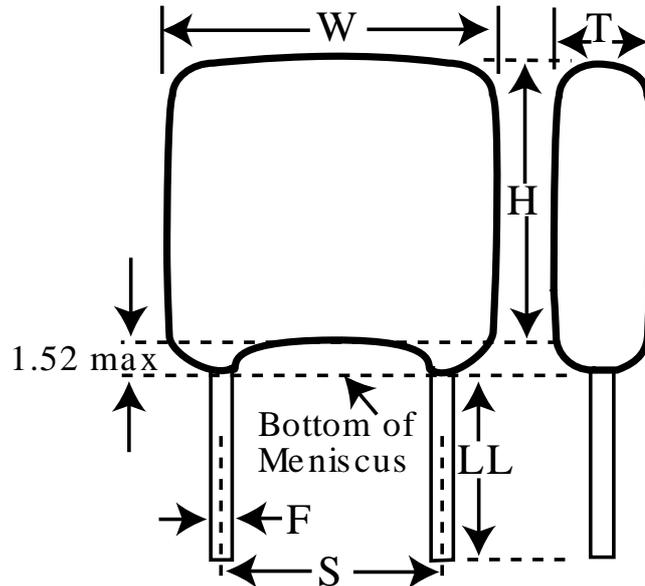

Dimensions (in)

Specifications

ID	Dimension	Tolerance	Manufacturer:	KEMET
W	0.2		Capacitance:	0.33 uF
H	0.26	max	Lead Spacing:	0.1"
T	0.125	max	Voltage:	50V
S	0.1	+/-0.03	Temperature Coefficient:	Z5U
LL	0.276	min	Tolerance:	+/-20%
F	0.02	+0.004/-0.001	Body Type:	Radial Conformal
			Lead Type:	PC-Leads
			Lead Form:	Straight Leads
			Termination Type:	Tin
			Package Kind:	Bulk
			Package Type:	Bag
			Package Quantity:	500