


DATA SHEET

TYPE: LC (Radial Lead- Polar)

MECHANICAL DIMENSIONS D×L 5×12

UNIT: mm

d: 0.5 mm

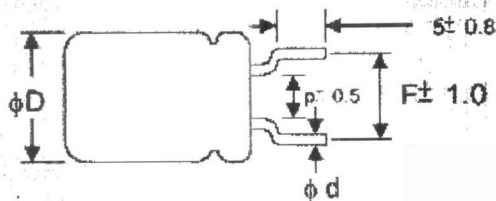

Formed lead code: FC

ELECTRICAL

Capacitance	4.7 μ F
Tolerance	at 120HZ +20% ~ - 20%
Working Voltage	63 WVDC
Operating Temperature	- 40°C to +85°C
D.C Leakage Current	After 3 Mins. 3uA Max.
Dissipation Factor TAN δ	0.10 at 20°C 120 HZ
Load Life	at 85°C 2000 Hours
Forming and cutting	5.0mm
Part No	LC-0512-4.7-63-MFC

APPROVED BY	DRAWN BY	REVISION	DATE
Joie	Yu Fang	Yi Xian	2007-12-11