

# Crimping pliers - CRIMPFOX 6 - 1212034

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Crimping pliers, for ferrules as per DIN 46228 section 1+4, 0.25 - 6.0 mm<sup>2</sup>, insertion from the side, trapezoidal crimp

## Product Features

- Comprehensive range of crimping pliers
- All ferrules can be optimally crimped with a minimum amount of effort even in the case of large conductor cross sections
- Consistently high crimping quality
- Marked die stations for precise processing of corresponding cross sections
- Unlockable pressure lock



## Key commercial data

<b>package_quantity</b>	1
<b>GTIN</b>	4046356453813

## Technical data

### Dimensions

<b>Length (b)</b>	198 mm
<b>Height</b>	59 mm
<b>Width (a)</b>	18 mm

### General

<b>Color</b>	black
<b>Compression</b>	Trapezoidal crimp
<b>Type of contact</b>	Ferrules
<b>Name</b>	Crimping position 1
<b>Min. cross section</b>	0.25 mm <sup>2</sup>
<b>Max. cross section</b>	0.75 mm <sup>2</sup>
<b>AWG min</b>	24
<b>AWG max</b>	20
<b>Name</b>	Crimping position 2
<b>Min. cross section</b>	1 mm <sup>2</sup>
<b>Max. cross section</b>	1.5 mm <sup>2</sup>

# Crimping pliers - CRIMPFOX 6 - 1212034

## Technical data

### General

<b>AWG min</b>	18
<b>AWG max</b>	16
<b>Name</b>	Crimping position 3
<b>Max. cross section</b>	2.5 mm <sup>2</sup>
<b>AWG max</b>	14
<b>Die station</b>	Crimping position 4
<b>Max. cross section</b>	4 mm <sup>2</sup>
<b>AWG max</b>	12
<b>Die station</b>	Crimping position 5
<b>Max. cross section</b>	6 mm <sup>2</sup>
<b>AWG max</b>	10

## classifications

### eCl@ss

<b>eCl@ss 4.0</b>	21040301
<b>eCl@ss 4.1</b>	21040301
<b>eCl@ss 5.0</b>	21040301
<b>eCl@ss 5.1</b>	21040301
<b>eCl@ss 6.0</b>	21043811
<b>eCl@ss 7.0</b>	21043811
<b>eCl@ss 8.0</b>	21043811

### ETIM

<b>ETIM 2.0</b>	EC001186
<b>ETIM 3.0</b>	EC001186
<b>ETIM 4.0</b>	EC001186
<b>ETIM 5.0</b>	EC000168

### UNSPSC

<b>UNSPSC 6.01</b>	27112118
<b>UNSPSC 7.0901</b>	27111518
<b>UNSPSC 11</b>	23171604
<b>UNSPSC 12.01</b>	27111518
<b>UNSPSC 13.2</b>	27111518

## approvals

GOST /

Approval details

# Crimping pliers - CRIMPFOX 6 - 1212034

approvals



accessories

**Die**

CRIMPFOX 6/DIE - 1212035



---

**Mounting material**

CRIMPFOX/ SPR-3 - 1212036




---

Drawings

## Crimping pliers - CRIMPFOX 6 - 1212034

Product drawing

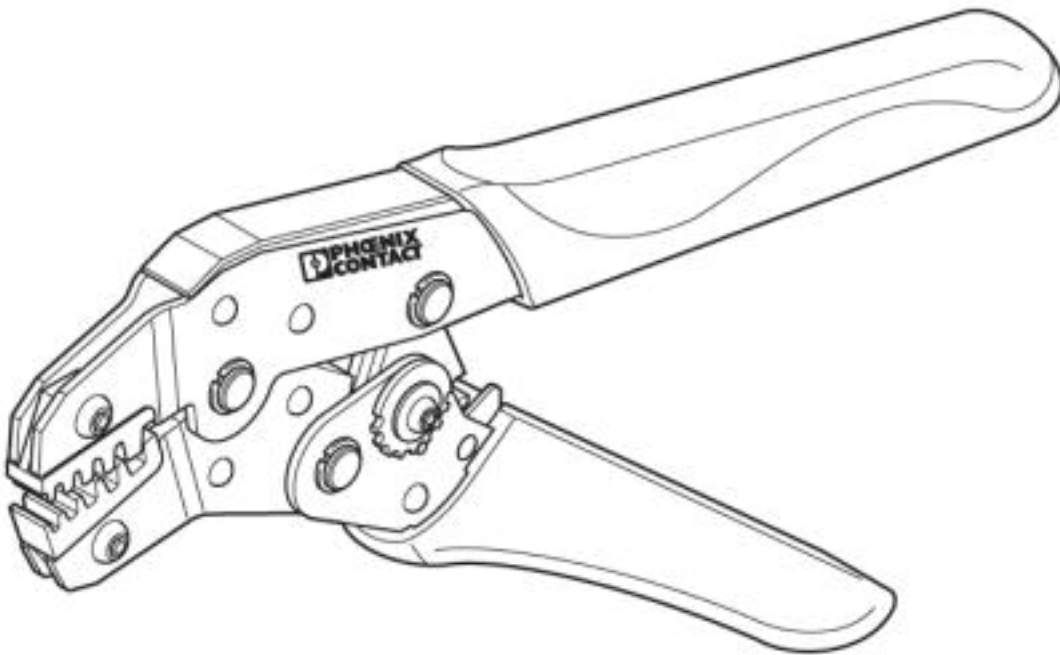

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>