

ECA 100 ipro H



Short description

Two-step small room fan with fully automatic humidity system, DN 100

Application examples

Bathroom, Shower, Sauna vestibule, Utility room

Article number 0084.0203


Technical data

Model	Humidity control
Air flow volume	78 m ³ /h / 92 m ³ /h
Rotating speed	2.100 1/min / 2.500 1/min
Speed controllable	–
Reversing capacity	–
SEC average	-24,18 kWh/(m ² *a)
Type of voltage	Alternating current
Rated voltage	230 V
Frequency	50 Hz
Nominal output	6 W / 8 W
I _{max}	0,06 A
Degree of protection	IP X5
Mains cable	3/5 x 1.5 mm ²
Installation site	Ceiling / Wall
Type of installation	Surface-mounted
Installation position	any
Material	Synthetic material
Colour	Traffic white, similar to RAL 9016
Weight	0,7 kg
Shutter	none
Nominal size	100 mm
Width	159 mm
Height	159 mm
Depth	130 mm
Airstream temperature at I _{Max}	40 °C
Overrun time	8 min / 17 min / 25 min (Overrun time of 0 min. available when using an optional switch (e.g. light switch))
Start delay	0 s / 50 s / 90 s / 120 s
Sound pressure level	27 dB(A) / 32 dB(A) (Distance 3 m, Free-field conditions)


ECA 100 ipro H

Packing unit	1 piece
Range	A
GTIN (EAN)	4012799842033

Characteristic curve

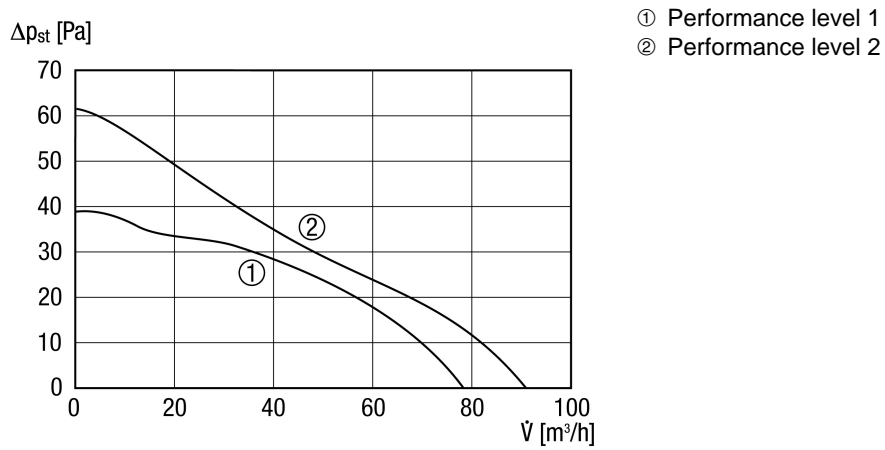

Dimensioned drawing [mm]

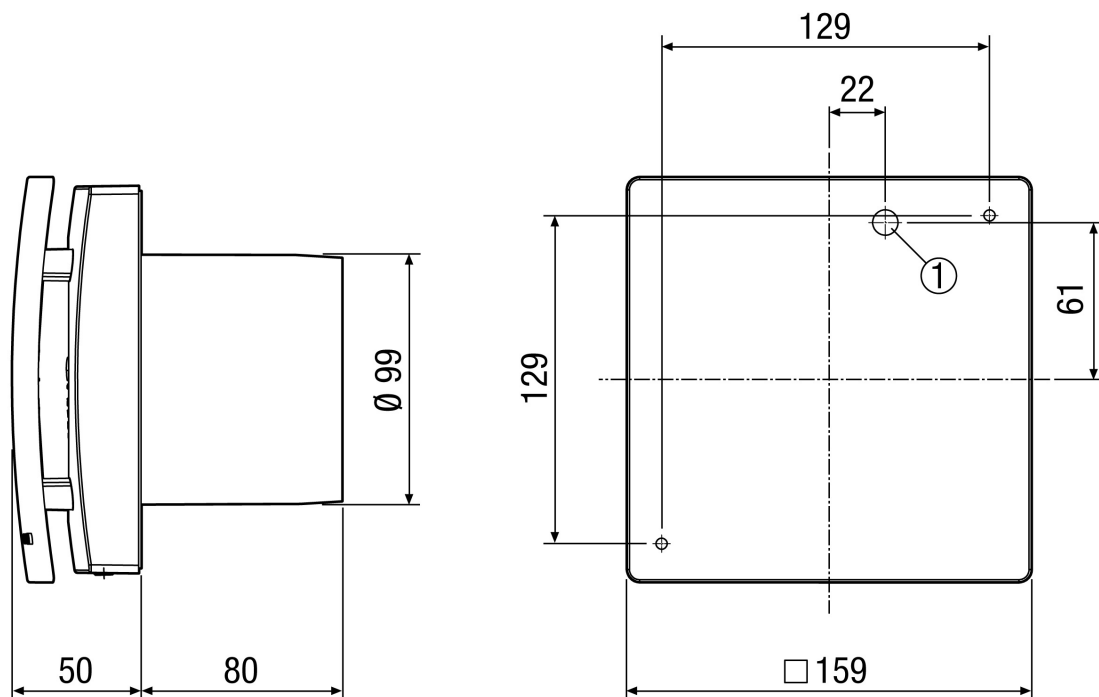



ECA 100 ipro H

① Cable entry