

PIC MSM-228 Threaded Magnet M8


Data

Housing Material	PA6.6		
Orientation	axially		
	Symbol	Unit	
Remanence	Br	mT	1190
Coercivity	HcB	kA / m	828
Coercivity	HcJ	kA / m	1274
Energy Product max.	BH	kJ / m ³	275
Magnetic Moment	M	10 ⁻⁵ Vs cm	1.50
Operating Temperature max.	T _{op}	°C	85
Temperature Coefficient	Tk (Br)	% / °C	-0.12

Nominal values unless otherwise specified.

Dimensions

in mm

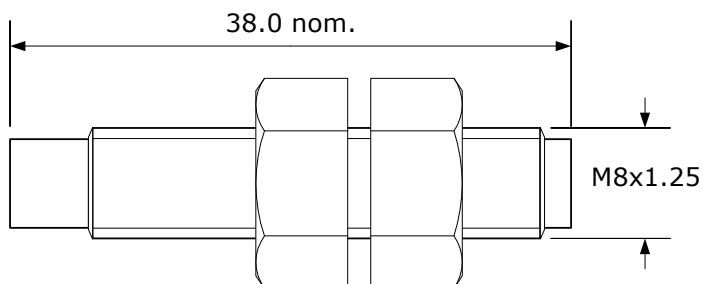

Ordering Information

Type	Nuts (packed separately)
PIC MSM-228	0 = without nuts 1 = with two nuts

example: PIC MSM-228-1 describes MSM-228, including 2 nuts