


Data sheet | Item number: 286-662

Current flow monitoring module; DC current flow monitoring module; 0.4 A ...
3.5 A; Relay with 1 make contact (1a)

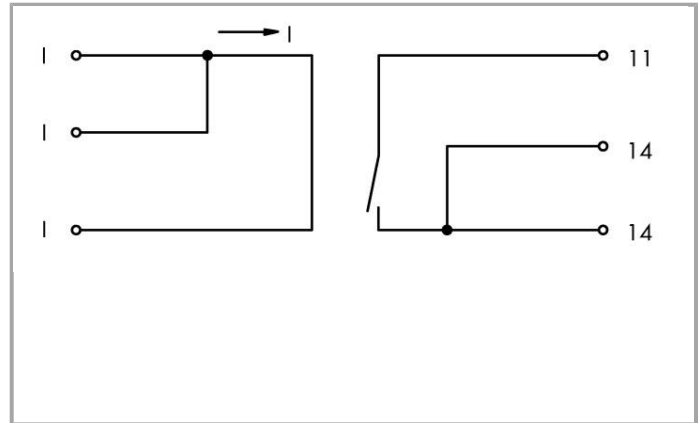


www.wago.com/286-662



RoHS Compliant

BOMcheck.net

Color: ■

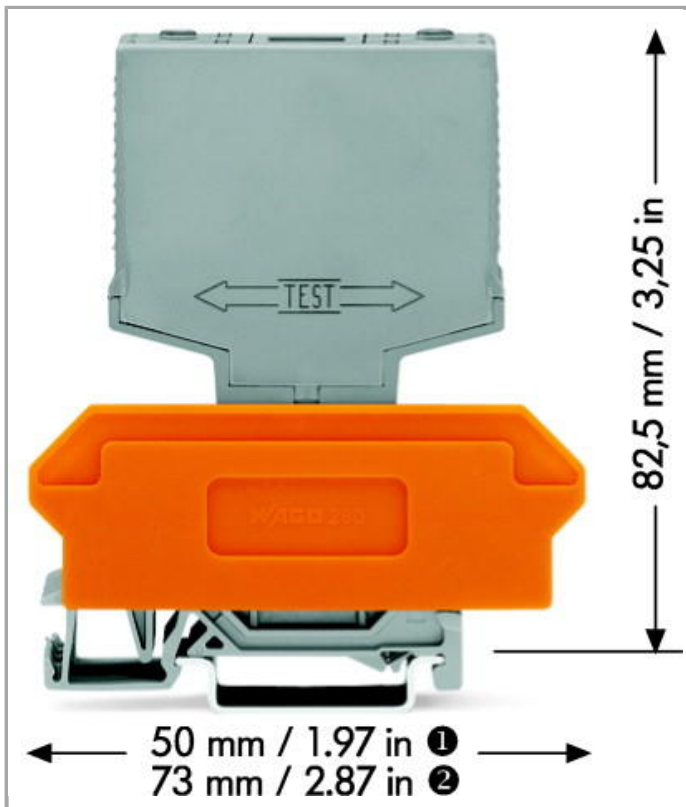

Data

Electrical data

Operating voltage	12 ... 28 VDC
Voltage drop at input	24 ... 210 mV
Max. measuring span	0.4 ... 3.5 ADC (-20 ... +40 °C); 0.4 ... 3 ADC (-20 ... +60 °C); 0.4 ... 2 ADC (-20 ... +70 °C)
Turn on / off point	0.35 A / 0.07 A
Response time	0.5ms
Number of make contacts/switch on contacts	1
Limiting continuous current	0.5 A
Max. switching voltage	200 VDC
Max. switching power (resistive)	10 WDC

Safety and protection:

Dielectric strength input/output (AC, 1 min)	1.5 kV _{rms}
--	-----------------------

Mechanical data

Type of mounting	Pluggable module for carrier terminal blocks
Housing design	Pluggable module for terminal blocks

Material Data

Color	light gray
Fire load	0.325 MJ
Weight	22.7 g

Environmental Requirements










Surrounding air (operating) temperature	-25 ... 40 °C
---	---------------

Commercial data

Country of origin	DE
GTIN	4045454415730
Customs Tariff No.	85364900990
Product Group	6 (Interface Electronics)

Compatible products

Marking accessories

	Item no.: 209-701 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701
	Item no.: 209-701/000-002 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-002
	Item no.: 209-701/000-005 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-005
	Item no.: 209-701/000-006 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-006
	Item no.: 209-701/000-007 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-007
	Item no.: 209-701/000-012 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-012
	Item no.: 209-701/000-017 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-017
	Item no.: 209-701/000-023 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-023
	Item no.: 209-701/000-024 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-701/000-024

General accessories



Item no.: 280-609

Terminal block for pluggable modules; 12-pole; with 4-conductor terminal blocks; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²

www.wago.com/280-609



Item no.: 280-619

Terminal block for pluggable modules; 6-pole; with 2-conductor terminal blocks; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²

www.wago.com/280-619



Item no.: 280-763

Terminal block for pluggable modules; 12-pole; with 4-conductor terminal blocks; with marker carrier; with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²

www.wago.com/280-763

Downloads

Documentation

Bid Text

286-662	Jan 15, 2016	DOC 24.6 kB	Download
Interface-Bausteine mit Sonderfunktionen			

Additional Information

Disposal; Electrical and electronic equipment, Packaging	Oct 15, 2018	265.8 kB	Download
--	--------------	----------	----------

Subject to changes.