


RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

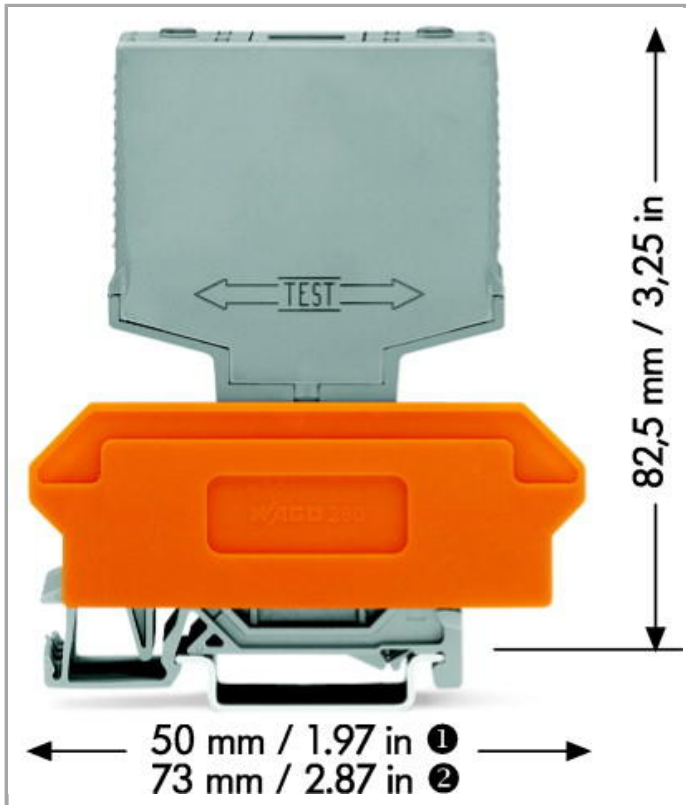

#### Item description

#### Note:

\*Max. admissible current per the manufacturer's data sheet. With all diodes loaded, the continuous current must be reduced.

#### Data

##### Electrical data

Operating voltage	≤ 250 V AC/DC
Peak reverse voltage	1000 V
Rectified current for each diode, resistive	1 A

##### Safety and protection:

Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	2

##### Geometrical Data

Width	10 mm / 0.394 inch
-------	--------------------

## Mechanical data

Type of mounting	Pluggable module for carrier terminal blocks
Housing design	Pluggable module for terminal blocks

## Material Data

Color	light gray
Fire load	0.342 MJ
Weight	14.414 g

## Environmental Requirements




Surrounding air (operating) temperature	-25 ... 40 °C
---	---------------

## Commercial data





Country of origin	DE
GTIN	4045454198046
Customs Tariff No.	85369010000
Product Group	6 (Interface Electronics)

## Compatible products

### General accessories

	<b>Item no.: 280-608</b> Terminal block for pluggable modules; 8-pole; with 4-conductor terminal blocks; with orange separator; <a href="http://www.wago.com/280-608">www.wago.com/280-608</a> for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup>
	<b>Item no.: 280-618</b> Terminal block for pluggable modules; 4-pole; with 2-conductor terminal blocks; with orange separator; <a href="http://www.wago.com/280-618">www.wago.com/280-618</a> for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup>
	<b>Item no.: 280-762</b> Terminal block for pluggable modules; 8-pole; with 4-conductor terminal blocks; with marker carrier; <a href="http://www.wago.com/280-762">www.wago.com/280-762</a> with orange separator; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup>

### Marking accessories

	<b>Item no.: 209-701</b> WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/209-701">www.wago.com/209-701</a>
	<b>Item no.: 209-701/000-002</b> WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/209-701/000-002">www.wago.com/209-701/000-002</a>
	<b>Item no.: 209-701/000-005</b> WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/209-701/000-005">www.wago.com/209-701/000-005</a>
	<b>Item no.: 209-701/000-006</b> WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/209-701/000-006">www.wago.com/209-701/000-006</a>



**Item no.: 209-701/000-007**  
WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/209-701/000-007](http://www.wago.com/209-701/000-007)



**Item no.: 209-701/000-012**  
WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/209-701/000-012](http://www.wago.com/209-701/000-012)



**Item no.: 209-701/000-017**  
WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/209-701/000-017](http://www.wago.com/209-701/000-017)



**Item no.: 209-701/000-023**  
WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/209-701/000-023](http://www.wago.com/209-701/000-023)



**Item no.: 209-701/000-024**  
WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/209-701/000-024](http://www.wago.com/209-701/000-024)

## Downloads

### Documentation

#### Additional Information

Disposal; Electrical and electronic equipment, Packaging

Oct 15, 2018

[Download](#)

265.8 kB

Subject to changes.