



Data sheet | Item number: 788-512

Relay module; Nominal input voltage: 24 VAC; 2 changeover contacts;  
Limiting continuous current: 8 A; Red status indicator; Module width: 15 mm

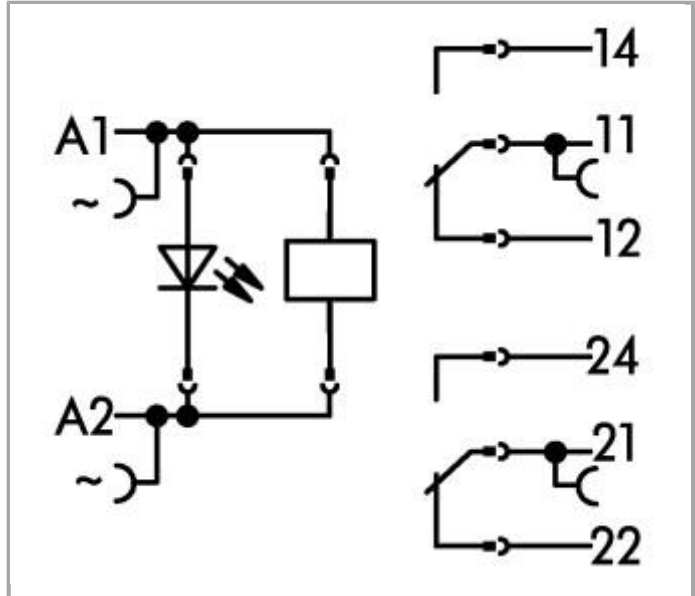



[www.wago.com/788-512](http://www.wago.com/788-512)

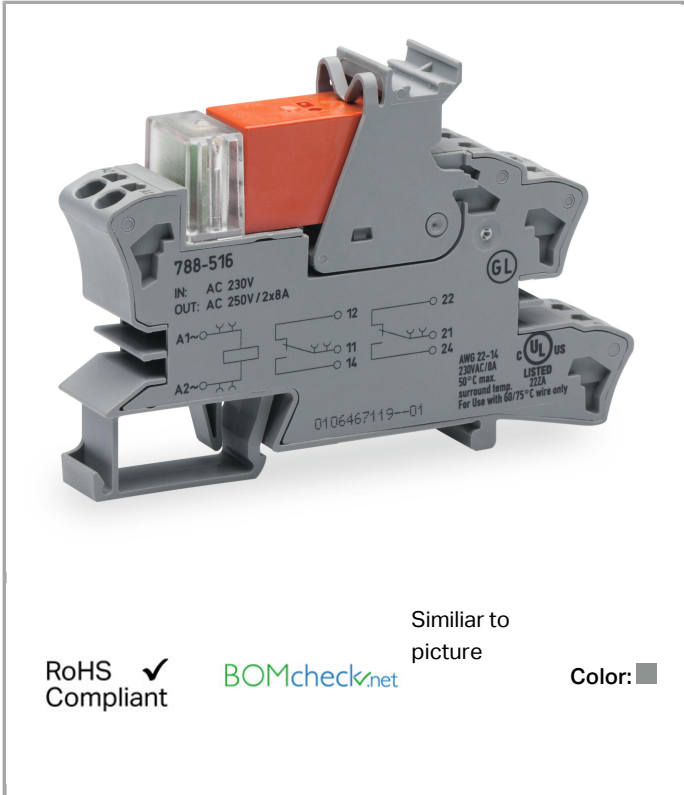

RoHS Compliant ✓

BOMcheck.net

Color: ■

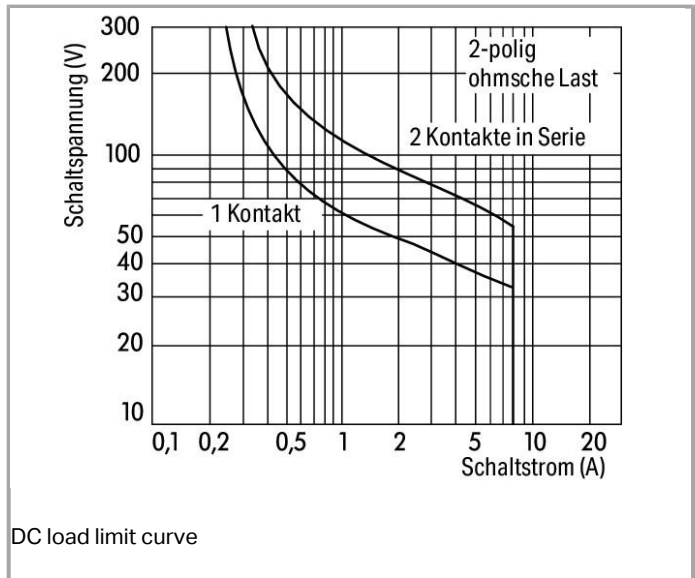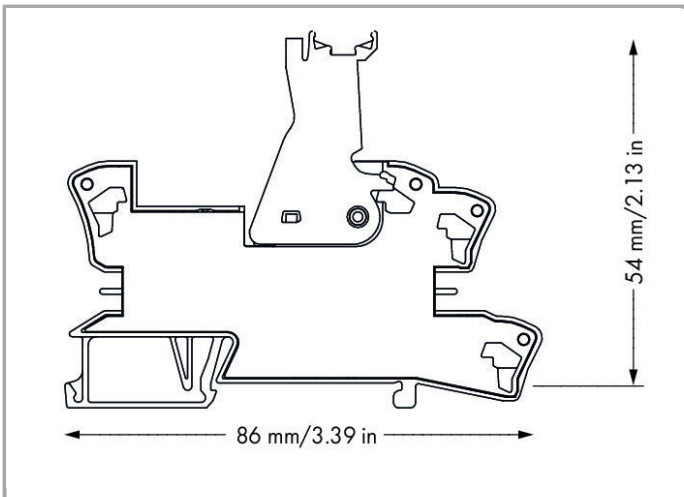

DC load limit curve

Item description

Note:

—

- Reinforced insulation between coil and contacts
- A separator plate (e.g., 209-191) must be used for voltages greater than 250 V between adjacent relay modules and for compliance with the reinforced insulation requirements.
- To protect the relay coils and contacts, inductive loads must be dampened with an effective protection circuit.

## Data

### Technical Data

#### Control circuit

|                                |            |
|--------------------------------|------------|
| Nominal input voltage $U_N$    | 24 VAC     |
| Input voltage range            | $\pm 10\%$ |
| Nominal input current at $U_N$ | 34 mA      |

#### Load circuit:

|   |  |
|---|--|
| Number of changeover/switchover contacts      | 2  |
| Contact material (relay)                      | AgNi 90/10                                   |
| Limiting continuous current                   | 8 A  |
| Max. make current (resistive)                 | 4 s 15 A (AC)                                |
| Max. switching voltage                        | 250 VAC                                      |
| Max. switching power (resistive)              | 2000 VAAC; DC see load limit curve           |
| Switching capacity                            | AC-15: 3 A / 250 VAC; DC-13: 2 A / 24 VDC    |
| Recommended minimum load                      | 12 V / 10 mA                                 |
| Pull-in time (typ.)                           | 8 ms   |
| Drop-out time (typ.)                          | 6 ms   |
| Bounce time (typ.)                            | 10 ms  |
| Electrical life (N.O.; resistive load; 23 °C) | $1 \times 10^3$ switching operations         |
| Mechanical life (N.O.; resistive load; 23 °C) | $30 \times 10^6$ switching operations        |
| Max. switching load with load/without load    | $6 \text{ min}^{-1} / 1200 \text{ min}^{-1}$ |

#### Signaling

|                   |         |
|-------------------|---------|
| Status indication | LED red |
|-------------------|---------|

#### Safety and protection:

|   |                             |
|---|-----------------------------|
| Rated voltage   | 250 V                       |
| Rated impulse voltage                                 | 4 kV                        |
| Pollution degree                                      | 3                           |
| Dielectric strength, control/load circuit (AC, 1 min) | $5 \text{ kV}_{\text{rms}}$ |
| Dielectric strength, control/load circuit (AC, 1 min) | $5 \text{ kV}_{\text{rms}}$ |

|  |                       |
|--|-----------------------|
| Dielectric strength open contact (AC, 1 min)       | 1 kV <sub>rms</sub>   |
| Dielectric strength open contact (AC, 1 min)       | 1 kV <sub>rms</sub>   |
| Dielectric strength, load/load circuit (AC, 1 min) | 2.5 kV <sub>rms</sub> |
| Dielectric strength, load/load circuit (AC, 1 min) | 2.5 kV <sub>rms</sub> |
| Degree of protection                               | IP20                  |

### Connection data

|                         |  |
|-------------------------|--|
| Connection technology   | Push-in CAGE CLAMP®                          |
| Solid conductor         | 0.34 ... 2.5 mm <sup>2</sup> / 22 ... 14 AWG |
| Fine-stranded conductor | 0.34 ... 2.5 mm <sup>2</sup> / 22 ... 14 AWG |
| Strip length            | 9 ... 10 mm / 0.35 ... 0.39 Inch             |

### Geometrical Data

|                                       |                    |
|---------------------------------------|--------------------|
| Width                                 | 15 mm / 0.591 inch |
| Height from upper-edge of DIN-35 rail | 54 mm / 2.126 inch |
| Depth                                 | 86 mm / 3.386 inch |

### Mechanical data

|                  |             |
|------------------|-------------|
| Type of mounting | DIN-35 rail |
|------------------|-------------|

### Material Data

|           |          |
|-----------|----------|
| Color     | gray     |
| Fire load | 0.89 MJ  |
| Weight    | 47.662 g |

### Environmental Requirements

|   |               |
|---|---------------|
| Surrounding air (operating) temperature at U <sub>N</sub> | -25 ... 70 °C |
| Surrounding air (storage) temperature                     | -40 ... 70 °C |
| Pollution degree  | 3             |

### Standards and specifications

|                          |  |
|--------------------------|--|
| Standards/specifications | EN 61010-2-201; EN 61810-1; EN 61373; GL; UL 508 |
|--------------------------|--|

### Elementary relay

|                       |         |
|-----------------------|---------|
| WAGO elementary relay | 788-172 |
|-----------------------|---------|

## Commercial data

|                    |                           |
|--------------------|---------------------------|
| Country of origin  | CN                        |
| GTIN               | 4045454424145             |
| Customs Tariff No. | 85364900990               |
| Product Group      | 6 (Interface Electronics) |

## Approvals / Certificates

### Ship Approvals






| Logo   | Approval  | Certificate name  |
|--|---|-------------------|
|    | <b>DNV GL</b><br>Det Norske Veritas, Germanischer Lloyd | TAA00001D1        |
|    | <b>NK</b><br>Nippon Kaiji Kyokai                        | TA17255M          |
|  | <b>PRS</b><br>Polski Rejestr Statkow                    | TE/1989/880590/13 |

### UL-Approvals

| Logo | Approval  | Certificate name |
|------|---|------------------|
|      | <b>UL</b><br>UL International Netherlands B.V. (ORDINARY LOCATIONS) | E175199 Sec.6    |

## Compatible products

### General accessories

|  |  |  |
|--|--|--|
|  | <b>Item no.: 209-145</b><br>Group marker carrier   | <a href="http://www.wago.com/209-145">www.wago.com/209-145</a> |
|  | <b>Item no.: 209-184</b><br>Protection cover   | <a href="http://www.wago.com/209-184">www.wago.com/209-184</a> |
|  | <b>Item no.: 249-105</b><br>Group marker carrier   | <a href="http://www.wago.com/249-105">www.wago.com/249-105</a> |
|  | <b>Item no.: 788-123</b><br>Accessories for relay modules; Operation status indicator: red | <a href="http://www.wago.com/788-123">www.wago.com/788-123</a> |
|  | <b>Item no.: 788-148</b><br>Filter module; RC filter element; Nominal voltage: 230 VAC     | <a href="http://www.wago.com/788-148">www.wago.com/788-148</a> |

### tools



**Item no.: 210-720**  
Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

[www.wago.com/210-720](http://www.wago.com/210-720)

### Jumper



**Item no.: 788-118**  
Comb-style jumper bar; 2-way (1-3); insulated

[www.wago.com/788-118](http://www.wago.com/788-118)



**Item no.: 859-402**  
Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402](http://www.wago.com/859-402)



**Item no.: 859-402/000-005**  
Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402/000-005](http://www.wago.com/859-402/000-005)



**Item no.: 859-402/000-006**  
Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402/000-006](http://www.wago.com/859-402/000-006)



**Item no.: 859-402/000-029**  
Push-in type jumper bar; 2-way; Nominal current 18 A; insulated

[www.wago.com/859-402/000-029](http://www.wago.com/859-402/000-029)

### ferrule



**Item no.: 216-241**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

[www.wago.com/216-241](http://www.wago.com/216-241)



**Item no.: 216-242**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

[www.wago.com/216-242](http://www.wago.com/216-242)



**Item no.: 216-243**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

[www.wago.com/216-243](http://www.wago.com/216-243)



**Item no.: 216-244**  
Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

[www.wago.com/216-244](http://www.wago.com/216-244)



**Item no.: 216-542**  
Twin ferrule; Sleeve for 2 x 1 mm<sup>2</sup> / AWG 2 x 18; red, insulated; 12 mm long

[www.wago.com/216-542](http://www.wago.com/216-542)

### Marking accessories



**Item no.: 2009-110**  
Marking strips; on reel; not stretchable; plain; snap-on type

[www.wago.com/2009-110](http://www.wago.com/2009-110)



**Item no.: 2009-115**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115](http://www.wago.com/2009-115)



















**Item no.: 2009-115/000-002**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type
















[www.wago.com/2009-115/000-002](http://www.wago.com/2009-115/000-002)



**Item no.: 2009-115/000-006**  
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-115/000-006](http://www.wago.com/2009-115/000-006)

|  |   |  |
|--|---|--|
|    | <p><b>Item no.: 2009-115/000-007</b><br/>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | <a href="http://www.wago.com/2009-115/000-007">www.wago.com/2009-115/000-007</a> |
|    | <p><b>Item no.: 2009-115/000-012</b><br/>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | <a href="http://www.wago.com/2009-115/000-012">www.wago.com/2009-115/000-012</a> |
|    | <p><b>Item no.: 2009-115/000-017</b><br/>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | <a href="http://www.wago.com/2009-115/000-017">www.wago.com/2009-115/000-017</a> |
|    | <p><b>Item no.: 2009-115/000-023</b><br/>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | <a href="http://www.wago.com/2009-115/000-023">www.wago.com/2009-115/000-023</a> |
|    | <p><b>Item no.: 209-128</b><br/>Adaptor</p>   | <a href="http://www.wago.com/209-128">www.wago.com/209-128</a>                   |
|    | <p><b>Item no.: 209-183</b><br/>Marker card</p>   | <a href="http://www.wago.com/209-183">www.wago.com/209-183</a>                   |
|    | <p><b>Item no.: 210-110</b><br/>Fiber-tip pen</p>   | <a href="http://www.wago.com/210-110">www.wago.com/210-110</a>                   |
|    | <p><b>Item no.: 793-501</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                             | <a href="http://www.wago.com/793-501">www.wago.com/793-501</a>                   |
|  | <p><b>Item no.: 793-501/000-002</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-002">www.wago.com/793-501/000-002</a>   |
|  | <p><b>Item no.: 793-501/000-005</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-005">www.wago.com/793-501/000-005</a>   |
|  | <p><b>Item no.: 793-501/000-006</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-006">www.wago.com/793-501/000-006</a>   |
|  | <p><b>Item no.: 793-501/000-007</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-007">www.wago.com/793-501/000-007</a>   |
|  | <p><b>Item no.: 793-501/000-012</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-012">www.wago.com/793-501/000-012</a>   |
|  | <p><b>Item no.: 793-501/000-017</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-017">www.wago.com/793-501/000-017</a>   |
|  | <p><b>Item no.: 793-501/000-023</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-023">www.wago.com/793-501/000-023</a>   |
|  | <p><b>Item no.: 793-501/000-024</b><br/>WMB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/793-501/000-024">www.wago.com/793-501/000-024</a>   |

|  |   |  |
|--|---|--|
|    | <p><b>Item no.: 793-502</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>          | <a href="http://www.wago.com/793-502">www.wago.com/793-502</a>                 |
|    | <p><b>Item no.: 793-502/000-002</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-002">www.wago.com/793-502/000-002</a> |
|    | <p><b>Item no.: 793-502/000-005</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-005">www.wago.com/793-502/000-005</a> |
|    | <p><b>Item no.: 793-502/000-006</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-006">www.wago.com/793-502/000-006</a> |
|    | <p><b>Item no.: 793-502/000-007</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-007">www.wago.com/793-502/000-007</a> |
|    | <p><b>Item no.: 793-502/000-012</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-012">www.wago.com/793-502/000-012</a> |
|    | <p><b>Item no.: 793-502/000-017</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-017">www.wago.com/793-502/000-017</a> |
|  | <p><b>Item no.: 793-502/000-023</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-023">www.wago.com/793-502/000-023</a> |
|  | <p><b>Item no.: 793-502/000-024</b><br/>WMB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type</p>  | <a href="http://www.wago.com/793-502/000-024">www.wago.com/793-502/000-024</a> |
|  | <p><b>Item no.: 793-503</b><br/>WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type</p>         | <a href="http://www.wago.com/793-503">www.wago.com/793-503</a>                 |
|  | <p><b>Item no.: 793-503/000-002</b><br/>WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type</p> | <a href="http://www.wago.com/793-503/000-002">www.wago.com/793-503/000-002</a> |
|  | <p><b>Item no.: 793-503/000-005</b><br/>WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type</p> | <a href="http://www.wago.com/793-503/000-005">www.wago.com/793-503/000-005</a> |
|  | <p><b>Item no.: 793-503/000-006</b><br/>WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type</p> | <a href="http://www.wago.com/793-503/000-006">www.wago.com/793-503/000-006</a> |
|  | <p><b>Item no.: 793-503/000-007</b><br/>WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type</p> | <a href="http://www.wago.com/793-503/000-007">www.wago.com/793-503/000-007</a> |
|  | <p><b>Item no.: 793-503/000-012</b><br/>WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type</p> | <a href="http://www.wago.com/793-503/000-012">www.wago.com/793-503/000-012</a> |



**Item no.: 793-503/000-017**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-017



**Item no.: 793-503/000-023**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-023



**Item no.: 793-503/000-024**

WMB marking card; as card; MARKED; 11 ... 20 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-503](http://www.wago.com/793-503)

/000-024



**Item no.: 793-504**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)



**Item no.: 793-504/000-002**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-002



**Item no.: 793-504/000-005**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-005



**Item no.: 793-504/000-006**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-006



**Item no.: 793-504/000-012**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-012



**Item no.: 793-504/000-017**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-017



**Item no.: 793-504/000-023**

WMB marking card; as card; MARKED; 21 ... 30 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-504](http://www.wago.com/793-504)

/000-023



**Item no.: 793-505**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)



**Item no.: 793-505/000-005**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-005



**Item no.: 793-505/000-006**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-006



**Item no.: 793-505/000-007**

WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-007



**Item no.: 793-505/000-012**
















WMB marking card; as card; MARKED; 31 ... 40 (10x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-505](http://www.wago.com/793-505)

/000-012

**Item no.: 793-506**



|  |   |  |
|--|---|--|
|    | WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type   | <a href="http://www.wago.com/793-506">www.wago.com/793-506</a>                   |
|    | <b>Item no.: 793-506/000-005</b><br>WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type         | <a href="http://www.wago.com/793-506/000-005">www.wago.com/793-506/000-005</a>   |
|    | <b>Item no.: 793-506/000-006</b><br>WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type         | <a href="http://www.wago.com/793-506/000-006">www.wago.com/793-506/000-006</a>   |
|    | <b>Item no.: 793-506/000-012</b><br>WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type         | <a href="http://www.wago.com/793-506/000-012">www.wago.com/793-506/000-012</a>   |
|    | <b>Item no.: 793-506/000-017</b><br>WMB marking card; as card; MARKED; 41 ... 50 (10x); not stretchable; Horizontal marking; snap-on type         | <a href="http://www.wago.com/793-506/000-017">www.wago.com/793-506/000-017</a>   |
|    | <b>Item no.: 793-5501</b><br>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type         | <a href="http://www.wago.com/793-5501">www.wago.com/793-5501</a>                 |
|    | <b>Item no.: 793-5501/000-002</b><br>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/793-5501/000-002">www.wago.com/793-5501/000-002</a> |
|  | <b>Item no.: 793-5501/000-005</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-005">www.wago.com/793-5501/000-005</a> |
|  | <b>Item no.: 793-5501/000-006</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-006">www.wago.com/793-5501/000-006</a> |
|  | <b>Item no.: 793-5501/000-007</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-007">www.wago.com/793-5501/000-007</a> |
|  | <b>Item no.: 793-5501/000-012</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-012">www.wago.com/793-5501/000-012</a> |
|  | <b>Item no.: 793-5501/000-014</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-014">www.wago.com/793-5501/000-014</a> |
|  | <b>Item no.: 793-5501/000-017</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-017">www.wago.com/793-5501/000-017</a> |
|  | <b>Item no.: 793-5501/000-023</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-023">www.wago.com/793-5501/000-023</a> |
|  | <b>Item no.: 793-5501/000-024</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type                                       | <a href="http://www.wago.com/793-5501/000-024">www.wago.com/793-5501/000-024</a> |



**Item no.: 793-566**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566](http://www.wago.com/793-566)



**Item no.: 793-566/000-002**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-002](http://www.wago.com/793-566/000-002)



**Item no.: 793-566/000-005**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-005](http://www.wago.com/793-566/000-005)



**Item no.: 793-566/000-006**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-006](http://www.wago.com/793-566/000-006)



**Item no.: 793-566/000-007**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-007](http://www.wago.com/793-566/000-007)



**Item no.: 793-566/000-012**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-012](http://www.wago.com/793-566/000-012)



**Item no.: 793-566/000-017**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-017](http://www.wago.com/793-566/000-017)



**Item no.: 793-566/000-023**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-023](http://www.wago.com/793-566/000-023)



**Item no.: 793-566/000-024**

WMB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

[www.wago.com/793-566/000-024](http://www.wago.com/793-566/000-024)

## Downloads

### Documentation

#### Bid Text

|                |              |         |          |
|----------------|--------------|---------|----------|
| 788-512        | Jan 15, 2016 | DOC     | Download |
| Relaisbaustein |              | 28.2 kB |          |

#### Instruction Leaflet

|                          |              |        |          |
|--------------------------|--------------|--------|----------|
| Socket with Relay or SSR | Sep 28, 2015 | PDF    | Download |
|                          |              | 2.1 MB |          |

#### Additional Information

|  |              |          |          |
|--|--------------|----------|----------|
| Disposal; Electrical and electronic equipment, Packaging | Oct 15, 2018 |          | Download |
|  |              | 265.8 kB |          |



**smartDATA**

**CAD data**

3D Download 788-512

URL

Download

---

Subject to changes.