


RIDERSERIES RCMKITP-I 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

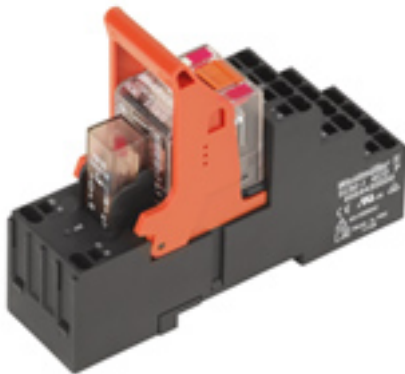

Modular system comprised of:

- relay socket for rail mounting
- LED indicator unit
- retaining clip
- plug-in relay
- markers

General ordering data

Order No.	8921150000
Type	RCMKITP-I 230VAC 4CO LD
Version	RIDERSERIES, Relays, No. of contacts: 4, CO contact with test button, AgNi 90/10, Rated control voltage: 230 V AC, Continuous current: 6 A, PUSH IN spring connection
GTIN (EAN)	403224869236 1
Qty.	10 pc(s).

RIDERSERIES
RCMKITP-I 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data
Ratings

Conductor connection system	PUSH IN spring connection	Humidity	40 °C / 93 % rel. humidity, no condensation
UL 94 flammability rating	V-0		

Dimensions and weights

Width	28 mm	Height	98 mm
Depth	79 mm	Net weight	97.45 g

Temperatures

Operating temperature	-40 °C...+70 °C	Storage temperature	-40 °C...+70 °C
-----------------------	-----------------	---------------------	-----------------

Connection data

Clamping range, rated connection	1.5 mm ²	Clamping range, rated connection, min.	0.75 mm ²
Clamping range, rated connection, max.	1.5 mm ²	Stripping length, rated connection	12 mm

Input

Rated control voltage	230 V AC	Rated current AC	4.3 mA
Coil resistance	19,465 Ω ± 15 %	Power rating	1.0 VA
Response / drop-out voltage AC coil	184.0 V / 69.0 V	Status indicator	Green LED = DC coil; red LED = AC coil

Output

Rated switching voltage	240 V AC	Max. switching voltage, AC	240 V
Continuous current	6 A	making current	12 A / 20 ms
Max. switching power	1500 VA	Sparkover time / Drop-out time	15 ms / 10 ms
Min. switching power	12 V / 10 mA	Max. switching frequency at rated load	0.1 Hz

Contact specifications

No. of contacts	4	Contact design	CO contact with test button
Contact material	AgNi 90/10	Mechanical service life	AC coil 20 x 10 ⁶ Switching cycles, DC coil 30 x 10 ⁶ Switching cycles

Insulation coordination

Rated voltage	250 V	Clearance and creepage distances for control side - load side	≥ 4 mm
Dielectric strength for control side - load side	2.5 KV _{eff} / 1 min.	Protection degree	IP 20
Insulating material group	IIIa	Pollution severity	2
Surge voltage category	III		

Other technical data

Version	with test button	Status indicator	Green LED = DC coil; red LED = AC coil
---------	------------------	------------------	--

**RIDERSERIES
RCMKITP-I 230VAC 4CO LD**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Further details of approvals / standards

Standards DIN EN 50178

Classifications

ETIM 2.0	EC001437	ETIM 3.0	EC001437
UNSPSC	30-21-19-17	eClass 4.1	40-02-06-14
eClass 5.1	27-37-16-01	eClass 6.0	27-37-16-01
eClass 7.0	27-37-16-01		

Approvals

Approvals



Downloads

Declaration of Conformity	K318_09_09.pdf
EPLAN	8921150000.ema
3-D model	


**RIDERSERIES
RCMKITP-I 230VAC 4CO LD**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com


Drawings

Electric symbol


AC-Version

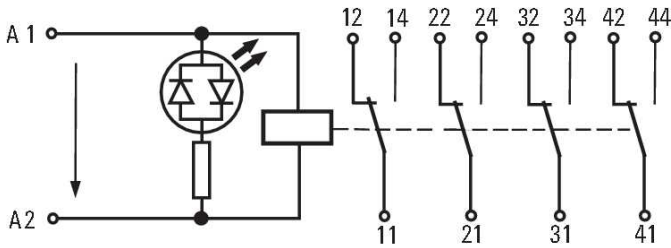


DC load breaking capacity

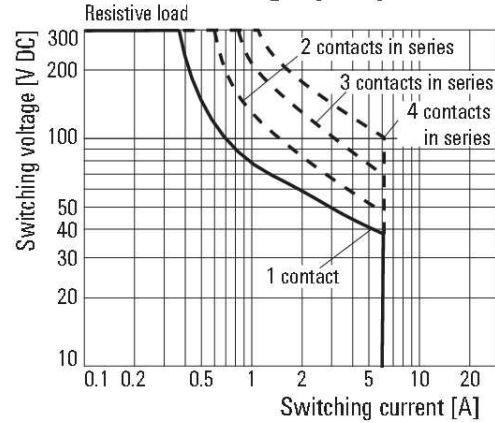


Derating curve

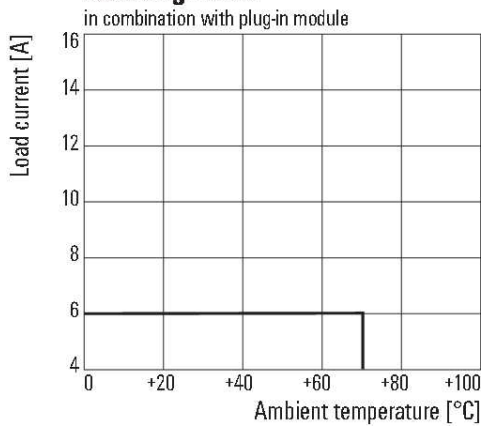

Operating voltage range AC

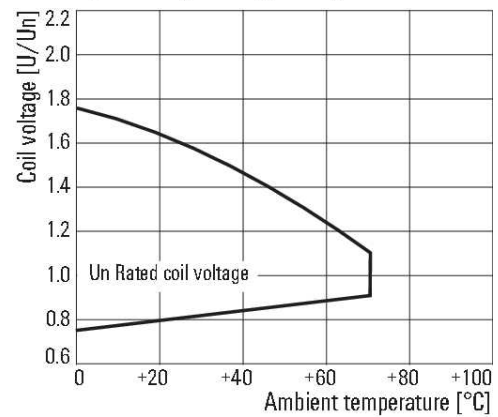

Electrical endurance

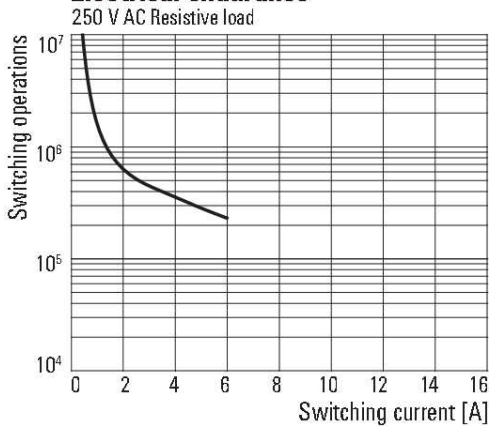

**RIDERSERIES
RCMKITP-I 230VAC 4CO LD**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

LED



Pluggable protective modules for the RIDERSERIES RCI / RCM relay base, with optional protective functions.

- With either green or red LED
- For UC supply voltage

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869650000	RIM-I 3 110/230VUC	RIDERSERIES, Accessories	4032248614592	10 pc(s).
8869660000	RIM-I 3 110/230VUC GN	RIDERSERIES, Accessories	4032248614721	10 pc(s).

Labelling clip



Labelling clip for marking RIDERSERIES RCM relays

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869460000	SCM-I MARK	RIDERSERIES, Markers	4032248614417	10 pc(s).

Metal retaining clip



Metal retaining clip for RIDERSERIES RCM relays

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869450000	SCM-I CLIP M	RIDERSERIES, Accessories	4032248614301	10 pc(s).

**RIDERSERIES
RCMKITP-I 230VAC 4CO LD**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

LED / Protective varistor



Pluggable protective modules for the RIDERSERIES RCI / RCM relay base, with optional protective functions.

- With protective varistor
- For UC supply voltage

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869750000	RIM-I 4 230VUC VAR	RIDERSERIES, Accessories	4032248606368	10 pc(s).

Plastic retaining clip



Plastic retaining clip for RIDERSERIES RCM relays

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869440000	SCM-I CLIP P	RIDERSERIES, Accessories	4032248614295	10 pc(s).

Base



Relay base for RIDERSERIES RCM relays

- 2, 3 and 4 CO contacts
- Screw and PUSH IN wire connection
- Standard and low heights

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869390000	SCM-I 4CO N	RIDERSERIES, Accessories,	4032248614257	10 pc(s).
		Continuous current: 6 A,		
		Screw connection		

**RIDERSERIES
RCMKITP-I 230VAC 4CO LD**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

[8869420000](#) SCM-I 4CO

RIDERSERIES, Accessories, 4032248614271 10 pc(s).
 Continuous current: 6 A,
 Screw connection

Protection module


Pluggable protective modules for the RIDERSERIES RCI / RCM relay base, with optional protective functions.

- Optionally with free-wheel diode, load resistor or RC filter

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8869580000	RIM-I 1 6/230V	RIDERSERIES, Accessories	4032248614523	10 pc(s).
8870830000	RIM-I 1 R 110/230V	RIDERSERIES, Accessories	4032248631674	10 pc(s).
8869790000	RIM-I 3 110/230VAC RC	RIDERSERIES, Accessories	4032248606337	10 pc(s).

Cross-connector


Cross-connector for bridging connections in the RIDERSERIES RCM

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
8870850000	SCM-I QV P	RIDERSERIES, Cross-connector	4032248631698	10 pc(s).
1132080000	SCM-I QV S	RIDERSERIES, Cross-connector	4032248912193	10 pc(s).