
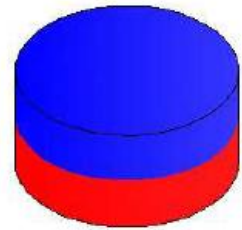


Data Sheet

NdFeB-Magnet Disc N45

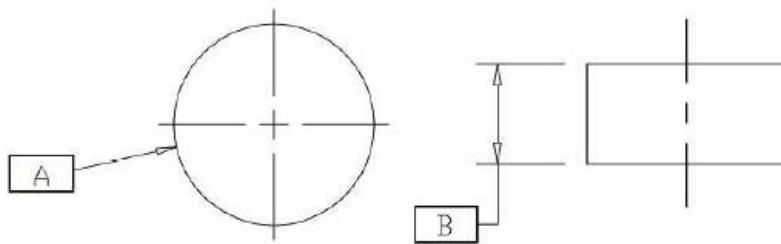

Dimension

Item no.	\varnothing (A)	Height (B)
505864 / 1566707	2mm	10mm
505865 / 1565125	2mm	5mm
505868 /	2mm	2mm

Data Sheet

1565126		
505869 / 1566708	5mm	20mm
505871 / 1565127	5mm	10mm
505874 / 1570690	5mm	5mm
505875 / 1565128	5mm	2mm
505876 / 1565129	10mm	10mm
505877 / 1564443	10mm	5mm
505878 / 1566709	10mm	2mm
505879 / 1570143	20mm	10mm
505881 / 1572114	20mm	5mm
506103 / 1566724	20mm	2mm

Grade	N45
Remanence Br	13.3 to 13.7 kGs
Coercivity bHc	≥11 kOe
Intrinsic Coercivity iHc	≥12 kOe
Max Energy Product BHmax	43 to 46 MGOe
Operating Temperature	max. 80°C
Tolerance	±0.1mm