
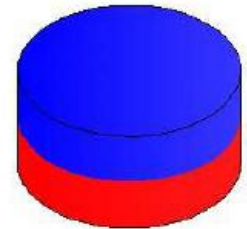


Data Sheet

NdFeB-Magnet Disc N35M

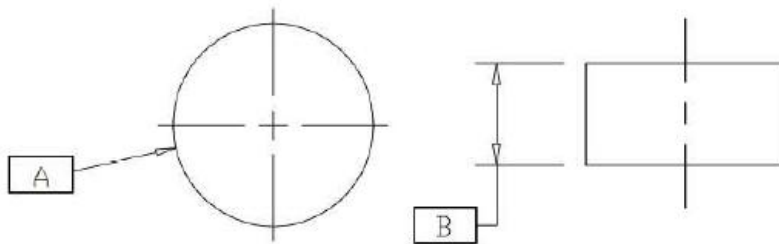

Dimension

Item no.	Ø (A)	Height (B)
505883	2mm	10mm
505886	2mm	5mm
505887 / 1566710	2mm	2mm

Data Sheet

505888 / 1570144	5mm	20mm
505890 / 1564444	5mm	10mm
505891 / 1571353	5mm	5mm
505892 / 1571354	5mm	2mm
505894 / 1572115	10mm	10mm
505895 / 1565130	10mm	5mm
505896 / 1565131	10mm	2mm
505902 / 1572116	20mm	10mm
505903 / 1566711	20mm	5mm
505904 / 1572117	20mm	2mm

Grade	N35M
Remanence Br	11.8 to 12.4 kGs
Coercivity bHc	≥10.9 kOe
Intrinsic Coercivity iHc	≥14 kOe
Max Energy Product BHmax	33 to 37 MGOe
Operating Temperature	max. 100°C
Tolerance	±0.1mm

Item no.: 505883 / 505886 / 505887 / 505888 / 505890 / 505891 / 505892 / 505894 / 505895 / 505896 /
505902 / 505903 / 505904 / 1564444 / 1565130 / 1565131 / 1566710 / 1570144 / 1571353 / 1571354 /
1572115 / 1572117 / 1572116 / 1566711 /

Data Sheet

