
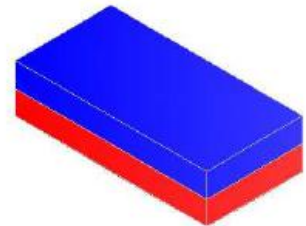
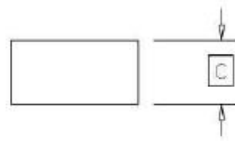


Data Sheet

NdFeB-Magnet Rectangular N35

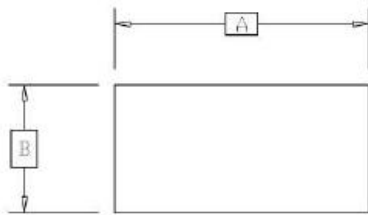

Data Sheet

Dimension

Item no.	Length (A)	Width (B)	Height (C)
505923 / 1564446	2mm	2mm	2mm
505926 / 1570691	5mm	5mm	5mm
505929	10mm	5mm	5mm
505930 / 1566714	10mm	10mm	5mm
505931 / 1572121	10mm	10mm	10mm
505932	20mm	5mm	5mm
505934	20mm	10mm	5mm
505936 / 1566715	20mm	10mm	10mm
505937	20mm	20mm	5mm
505940	20mm	20mm	10mm
505941	20mm	20mm	20mm

Grade	N35
Remanence Br	11.8 to 12.4 kGs
Coercivity bHc	≥10.9 kOe
Intrinsic Coercivity iHc	≥12 kOe
Max Energy Product BHmax	33 to 37 MGOe
Operating Temperature	max. 80°C
Tolerance	±0.1mm