
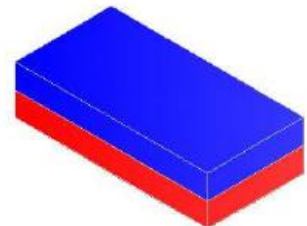
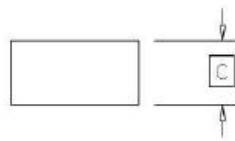


Data Sheet

NdFeB-Magnet Rectangular N45

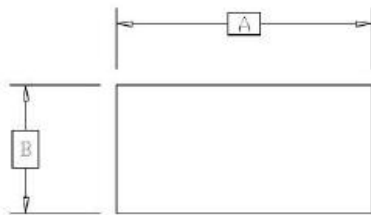

Data Sheet

Dimension

Item no.	Length (A)	Width (B)	Height (C)
505944 / 1570145	2mm	2mm	2mm
505945 / 1566716	5mm	5mm	5mm
505946 / 1564447	10mm	5mm	5mm
505948	10mm	10mm	5mm
505949	10mm	10mm	10mm
505950	20mm	5mm	5mm
505954	20mm	10mm	5mm
505955	20mm	10mm	10mm
505956	20mm	20mm	5mm
505957	20mm	20mm	10mm
505958 / 1572122	20mm	20mm	20mm

Grade	N45
Remanence Br	13.3 to 13.7 kGs
Coercivity bHc	≥11 kOe
Intrinsic Coercivity iHc	≥12 kOe
Max Energy Product BHmax	43 to 46 MGOe
Operating Temperature	max. 80°C
Tolerance	±0.1mm