
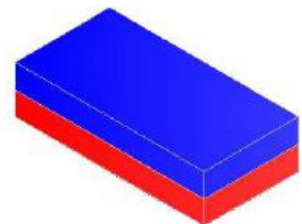
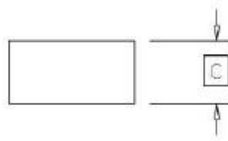


Data Sheet

NdFeB-Magnet Rectangular N35M

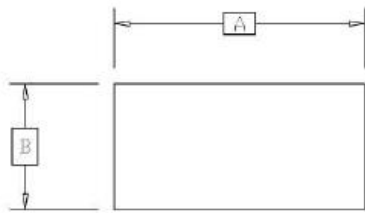

Data Sheet

Dimension

Item no.	Length (A)	Width (B)	Height (C)
505959	2mm	2mm	2mm
505962	5mm	5mm	5mm
505963 / 1566717	10mm	5mm	5mm
505964	10mm	10mm	5mm
505967	10mm	10mm	10mm
505969	20mm	5mm	5mm
505970	20mm	10mm	5mm
505971	20mm	10mm	10mm
505972	20mm	20mm	5mm
505974	20mm	20mm	10mm
505975	20mm	20mm	20mm

Grade	N35M
Remanence Br	11.8 to 12.4 kGs
Coercivity bHc	≥10.9 kOe
Intrinsic Coercivity iHc	≥14 kOe
Max Energy Product BHmax	33 to 37 MGOe
Operating Temperature	max. 100°C
Tolerance	±0.1mm