
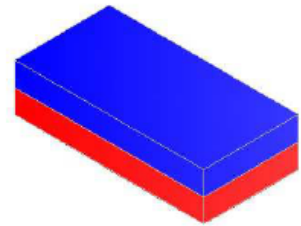


## Data Sheet

### NdFeB-Magnet Rectangular N35EH

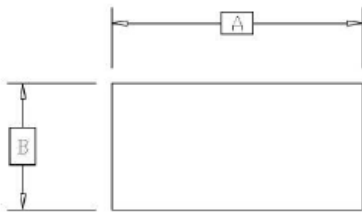

#### Dimension

Item no.	Length (A)	Width (B)	Height (C)
505976 / 1566718	2mm	2mm	2mm
505980 / 1564448	5mm	5mm	5mm
505981	10mm	5mm	5mm
505982	10mm	10mm	5mm

## Data Sheet

505983	10mm	10mm	10mm
505984	20mm	5mm	5mm
505985	20mm	10mm	5mm
505988	20mm	10mm	10mm
505989	20mm	20mm	5mm
505990	20mm	20mm	10mm
505996	20mm	20mm	20mm

Grade .....	N35EH
Remanence Br .....	11.8 to 12 kGs
Coercivity bHc .....	≥11.2 kOe
Intrinsic Coercivity iHc .....	≥30 kOe
Max Energy Product BHmax .....	33 to 36 MGOe
Operating Temperature .....	max. 200°C
Tolerance .....	±0.1mm