
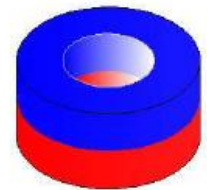


## Data Sheet

### NdFeB-Magnet Ring N45

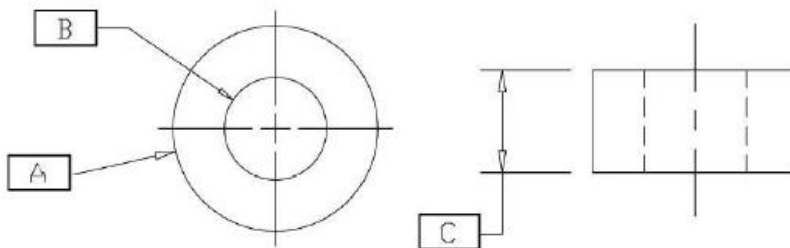

#### Dimension

Item no.	Outer Ø (A)	Inner Ø (B)	Height (C)
506005 / 1570146	10mm	5mm	10mm
506009 / 1571357	10mm	5mm	5mm
506011 / 1566719	10mm	5mm	2mm

## Data Sheet

---

506012 / 1570147	20mm	10mm	10mm
506013 / 1566720	20mm	10mm	5mm
506014 / 1566721	20mm	10mm	2mm

Grade .....N45  
 Remanence Br ..... 13.3 to 13.7 kGs  
 Coercivity bHc ..... $\geq 11$  kOe  
 Intrinsic Coercivity iHc ..... $\geq 12$  kOe  
 Max Energy Product BHmax ..... 43 to 46 MGOe  
 Operating Temperature .....max. 80°C  
 Tolerance ..... $\pm 0.1$ mm