
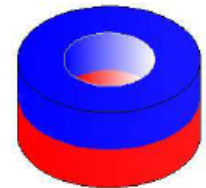


## Data Sheet

### NdFeB-Magnet Ring N35

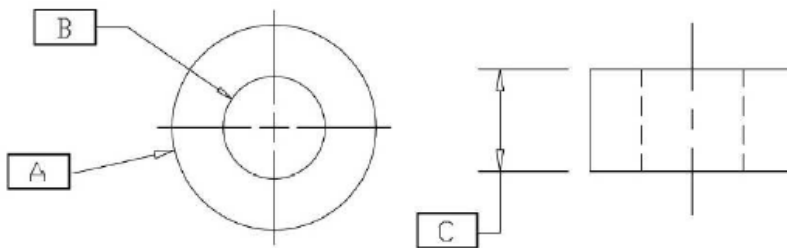

#### Dimension

Item no.	Outer Ø (A)	Inner Ø (B)	Height (C)
505997	10mm	5mm	10mm
506105 / 1571358	10mm	5mm	5mm
505999 / 1572123	10mm	5mm	2mm
506000	20mm	10mm	10mm
506002	20mm	10mm	5mm
506004	20mm	10mm	2mm

## Data Sheet

---

Grade .....	N35
Remanence Br .....	11.8 to 12.4 kGs
Coercivity bHc .....	$\geq 10.9$ kOe
Intrinsic Coercivity iHc .....	$\geq 12$ kOe
Max Energy Product BHmax .....	33 to 37 MGOe
Operating Temperature .....	max. 80°C
Tolerance .....	$\pm 0.1$ mm