

# Linear Solenoids

## AC laminated Solenoids

Useable as pull and push - version


Very strong

Extremly solid

ITS-LL 3833

**M**

### Type

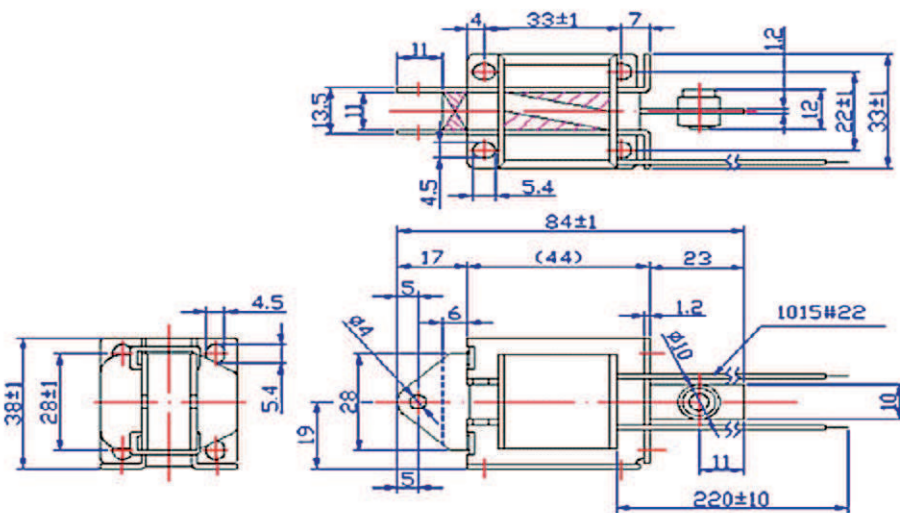

### Force-stroke-diagram (N/mm)

### Description

Heavy duty AC laminated solenoid for active current supply.

No rectifier necessary.

Available forces from 5-60N

### Coil Data

Frequency range: 50 – 60 HZ

Nominal force (N): 5

Nominal stroke (mm): 10

Length x width x height (mm): 84 x 33 x 38

Nomnial current (VAC)	Inrush current (A)	Holding current (A)
110	1,10	0.23
220	0,65	0.12

### Special development

Do you like a costum designed version (for example frame, force, duty cycle and so on) please send us this form:

[Checklist \(PDF, 390 kB\)](#)