

Cable Probe Type 02 / Pt 100


Product-Data

| | |
|-------------------------------|---|
| Sensor element : | Pt 100 Class B |
| Temperature range: | -50...+180 °C |
| Probe length: | 70 mm |
| Installation length: | 40 mm |
| Diameter Installation length: | 3 mm |
| Probe tube material: | Stainless Steel 1.4305 |
| Connecting cable: | Silicone insulated Ø 4.5 mm / 2 x 0.25 mm ² |
| Connecting cable length: | 2 meters |
| Tmax connecting cable: | +180 °C |
| Plug: | open wire ends |
| Ingress protection EN 60529: | IP 67 transition probe tube to connecting cable |
| Accuracy: | Class B DIN IEC 60751 +/- 0.3 °C |
| | |
| | |

Order-Information

| | |
|---------------------|-------------|
| TSG-Order-Number | 8006 1101 |
| Conrad-Order-Number | 50 77 70-XX |

dimensions

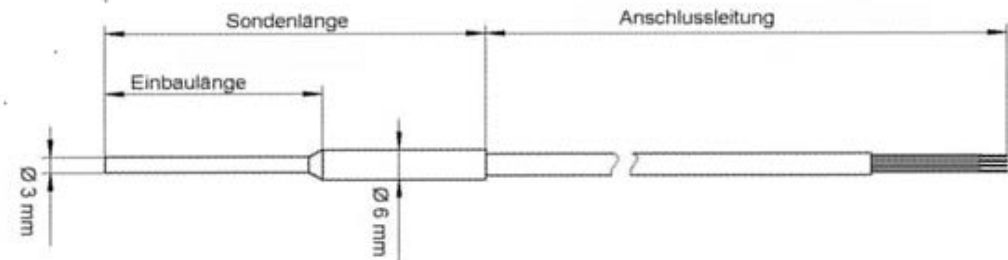

picture



example of installation

